


Indoor/Outdoor Vinyl (B-595)

For general facility and safety identification: Our best industrial vinyl yet.

- Durable, low-shrink vinyl with our most aggressive adhesive
- Conforms to irregular, curved, rough and highly textured surfaces (painted cinder blocks, uneven wood, textured plastics, paper-jacketed pipes, powder-coated surfaces)
- Adheres to “difficult” low-surface energy items (PVC piping, blow-molded equipment cases, ABS plastics, recycled plastics)

Service temp: -40°F to 180°F Application temp: 0°F to 180°F
Average Outdoor Durability: 8-10 year outdoor vinyl label durability.

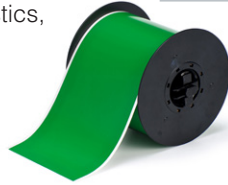

Facility and Safety Applications:
 5S Labels
 Pipe Markers
 Safety & Warning Labels
 Equipment & Panel Labels
 Arc Flash & Chemical Labels
 And More!

Fits Printer Model(s)	Diagram	Catalog #	Color	Label Width A Inch (mm)	Roll Length B Inch (mm)	Labels Per Roll	Rec. Ribbon
BBP31, BBP33	Fig. 33	B30C-500-595-WT	White	0.500 (12.7)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-1125-595-WT	White	1.125 (28.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-2250-595-WT	White	2.250 (57.5)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-3000-595-WT	White	3.000 (76.2)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-4000-595-WT	White	4.000 (101.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-500-595-YL	Yellow	0.500 (12.7)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-1125-595-YL	Yellow	1.125 (28.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-2250-595-YL	Yellow	2.250 (57.5)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-3000-595-YL	Yellow	3.000 (76.2)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-4000-595-YL	Yellow	4.000 (101.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-500-595-RD	Red	0.500 (12.7)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-1125-595-RD	Red	1.125 (28.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-2250-595-RD	Red	2.250 (57.5)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-4000-595-RD	Red	4.000 (101.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-500-595-BL	Blue	0.500 (12.7)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-1125-595-BL	Blue	1.125 (28.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-2250-595-BL	Blue	2.250 (57.5)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-4000-595-BL	Blue	4.000 (101.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-500-595-GN	Green	0.500 (12.7)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-1125-595-GN	Green	1.125 (28.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-2250-595-GN	Green	2.250 (57.5)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-4000-595-GN	Green	4.000 (101.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-500-595-OR	Orange	0.500 (12.7)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-1125-595-OR	Orange	1.125 (28.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-2250-595-OR	Orange	2.250 (57.5)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-4000-595-OR	Orange	4.000 (101.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-500-595-BK	Black	0.500 (12.7)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-1125-595-BK	Black	1.125 (28.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-2250-595-BK	Black	2.250 (57.5)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-4000-595-BK	Black	4.000 (101.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-500-595-BR	Brown	0.500 (12.7)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-1125-595-BR	Brown	1.125 (28.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-2250-595-BR	Brown	2.250 (57.5)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-4000-595-BR	Brown	4.000 (101.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-500-595-GD	Gold	0.500 (12.7)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-1125-595-GD	Gold	1.125 (28.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-2250-595-GD	Gold	2.250 (57.5)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-4000-595-GD	Gold	4.000 (101.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-500-595-GY	Gray	0.500 (12.7)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-1125-595-GY	Gray	1.125 (28.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-2250-595-GY	Gray	2.250 (57.5)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-4000-595-GY	Gray	4.000 (101.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-500-595-PL	Purple	0.500 (12.7)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-1125-595-PL	Purple	1.125 (28.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-2250-595-PL	Purple	2.250 (57.5)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-4000-595-PL	Purple	4.000 (101.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-500-595-CL	Clear //	0.500 (12.7)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-1125-595-CL	Clear //	1.125 (28.6)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-2250-595-CL	Clear //	2.250 (57.5)	100ft. (30.5m)	- continuous supply -	B30-R10000
BBP31, BBP33	Fig. 33	B30C-4000-595-CL	Clear //	4.000 (101.6)	100ft. (30.5m)	- continuous supply -	B30-R10000

 


Figure 33

U.S. Patent Nos. 5,823,689; 6,570,602. Additional Patents Pending.