

IEC Pin and Sleeve

60A, 3 Phase 250V, 3 Pole, 4 Wire

Low Profile Pin and Sleeve Plug

HUBBELL

Features

- Solid one-piece pins for reliable electrical contact
- Integrated Cord Grip limits strain on terminals

Ordering Information

Description	UPC	Catalog Number
Low Profile Pin and Sleeve, 60A 250V, 3P4W	783585507804	A460P9

Device Color
Blue




Specifications

Case	Zytel® 101 Nylon
Shroud	Zytel® 101 Nylon
Pins	Brass CDA #360
Pin and Carrier	High-Impact Thermoset
Terminal Screws	Stainless Steel

Performance

Electrical	
Current Interrupting	Certified for current interruption at full rated current
Dielectric Voltage	Withstands 3,000V AC
Max Working Voltage	250V RMS
Mechanical	
Impact Resistance	Per CSA C22.2 No. 182.1 / UL1682
Product Identification	Ratings are a permanent part of the device housing
Terminal Identification	Terminals identified in accordance with North American convention
Environmental	
Flammability	HB or better per UL 94 or CSA C22.2 No. 0.17
Ingress Protection	IP22 Suitability
Operating Temperatures	Max. Continuous +75°C; Min. -40°C w/o impact

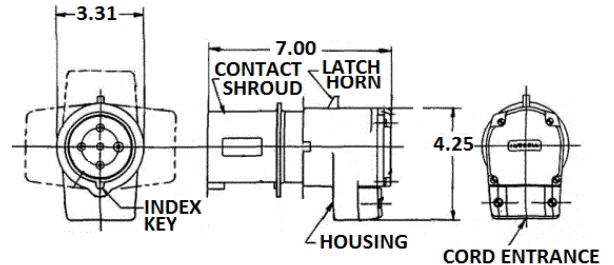

Online Resources

Customer Use Drawing
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

