



CRIMP CONNECTORS - DC SERIES



UL Listing No. E196862



CSA File No. 213637

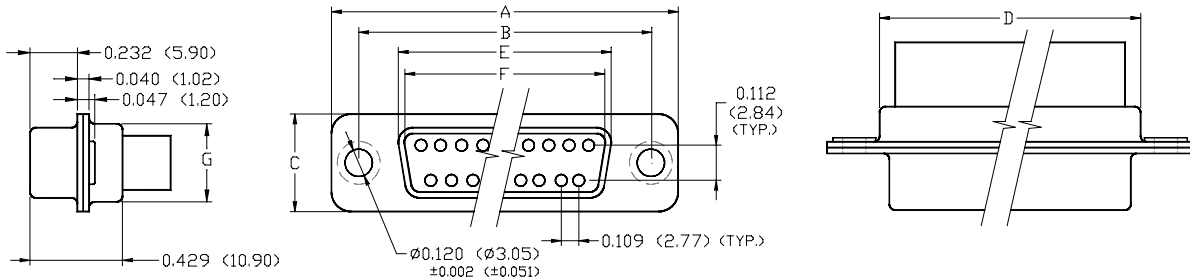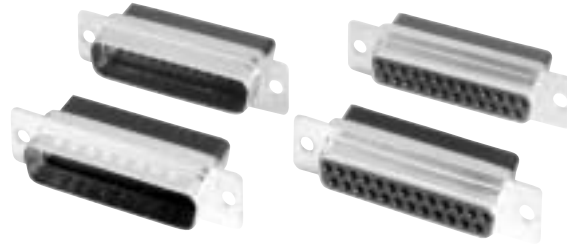

SPECIFICATIONS:

MECHANICAL

Shell: Steel
 Finish: Yellow Zinc Chromate or Tin Plated.
 Insulator: Glass Filled PBT UL94V-0.
 Temperature Range: -55° to +105° C.
 Contacts: See Page 30

ELECTRICAL

Voltage Rating: 300 VDC.
 Current Rating: 3 Amps.
 IR: > 3000 Meg OHms.
 CR: < 15 Milliohms.

CRIMP CONNECTORS - DC SERIES - DIMENSIONS							INCHES [MM]	
No. of Contacts	Shell Size	A ±0.005 [±0.127]	B ±0.005 [±0.127]	C ±0.005 [±0.127]	D ±0.005 [±0.127]	E Max. Female ±0.005 [±0.127]	F Min. Male ±0.005 [±0.127]	G ±0.005 [±0.127]
9	E	1.213 [30.81]	0.984 [24.99]	0.494 [12.55]	0.759 [19.28]	0.643 [16.33]	0.666 [16.92]	0.422 [10.72]
15	A	1.541 [39.14]	1.310 [33.27]	0.494 [12.55]	1.089 [27.65]	0.971 [24.66]	0.994 [25.25]	0.422 [10.72]
25	B	2.088 [53.04]	1.850 [46.99]	0.494 [12.55]	1.626 [41.30]	1.511 [38.38]	1.534 [38.96]	0.422 [10.72]
37	C	2.730 [69.34]	2.500 [63.50]	0.494 [12.55]	2.261 [57.44]	2.159 [54.84]	2.182 [55.42]	0.422 [10.72]
50	D	2.638 [67.00]	2.406 [61.11]	0.605 [15.37]	2.178 [55.32]	2.064 [52.43]	2.079 [52.81]	0.533 [13.54]

ORDER INFORMATION

