



New Products 2011




C7050CP 24-LED Area/Emergency Lantern



60 LUMENS	50 HOURS	4x C	7.5 INCHES
Light Output	Runtime	Battery	Length

- 24 high quality LEDs
- Push button on/off
- Metal cage protects plastic globe
- Durable casing
- Built-in hanger
- Batteries not included

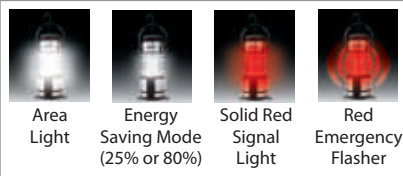

Area Light Energy Saving Mode (25% or 80%) Solid Red Signal Light Red Emergency Flasher

C7040CP 8-LED Mini Area Lantern



17 LUMENS	30 HOURS	4x AA	5.75 INCHES
Light Output	Runtime	Battery	Length

- 8 high quality LEDs
- Push button on/off
- Protective cage shields plastic globe
- Durable casing
- Batteries not included



Area Light Hi (7 LEDs) or Low (4 LEDs) Solid Red Signal Light Red Emergency Flasher

C7044CP Emergency Stretch Light



15 LUMENS	40 HOURS	4x AAA	4.5 INCHES
Light Output	Runtime	Battery	Length

- 6 high quality LEDs; 4 white, 2 red
- Push button on/off
- Includes lanyard
- Open, use as an area light
- High quality LED
- Weatherproof, corrosion resistant rubber and polymer casing
- Batteries not included
- Closed, use as a handheld flashlight




Area Light Solid Red Signal Light Red Emergency Flasher

CE7124HGB Emergency Area Light



Up to 125 LUMENS	100 HOURS	4x D
Light Output	Runtime	Battery

 - Smart Dial Switch System
- Battery life indicator
- Modes:
 - Hi bright white
 - VLT –Variable Light Output (5%-100%)
 - Red LED Flashing
 - Red LED Solid
- Batteries not included



Full Power Emergency AreaLight Low Power Area Light Solid Red Signal Light Red Emergency Flasher

TT8604CP L4 Focus Beam Flashlight

295ft	25	26	3xAAA	5.25
Beam Distance	LUMENS	HOURS	Battery	LENGTH



Rear Power Switch

- Twist for spot or flood beam
- Advanced Focus System™
- Weatherproof, corrosion resistant polymer casing
- Batteries included

TT8606CP L6 Focus Beam Flashlight

394ft	105	8	2xAA	6.3
Beam Distance	LUMENS	HOURS	Battery	LENGTH



Rear twist Switch

High intensity LED white beam

C2899CP (Also available in black titanium coated. LED Micro Pliers™ Version C2899BCP)



- Built in LED light (click for constant on)
- 400 series stainless steel construction
- Sure grip rubber handle inlays
- Spring loaded pliers head for easy one-handed operation
- Includes LED light in handle, pliers, wire cutter, main knife blade, saw blade, key ring, Philips screwdriver, bottle opener with flathead screwdriver tip and wire stripper, awl, file with nail pick, can opener with small flathead screwdriver tip, can opener
- Light takes two (2) CR1220 batteries
- 3 inches closed

C5799CP (Also available in black titanium coated. LED Pocket Pliers™ Version C5799BCP)



- Built in LED light (click for constant on)
- 400 series stainless steel construction
- Sure grip rubber handle inlays
- Spring loaded pliers head for easy one-handed operation
- Includes LED light in handle, pliers, wire cutter, main knife blade, file blade with wire stripper, flathead screwdriver, awl, small flathead screwdriver, can opener with screwdriver tip, Phillips screwdriver, bottle opener with flathead screwdriver and wire stripper, saw blade, scissors
- Light takes two (2) CR1220 batteries
- 4 inches closed

C07BCP
Black Skeleton
Folder Knife



- Open-frame handle
- 4.25 inches closed
- 7 inches overall

C22BCP
Black Z-Frame Knife



- Open-frame handle
- 3.5 inches closed
- 5.87 inches overall

C20136MBCP
Black X Frame Knife



- Cutout handle for lighter weight
- 3.5 inches closed
- 6.0 inches overall

- Titanium coated 400 series stainless steel drop point blade with partial serration
- Open-frame handle
- Thumb stud for one-handed opening
- Belt clip
- Liner lock



C09CP
Folding Knife w/ Carabiner



- Titanium coated 400 series stainless steel drop point blade
- Anodized aluminum handle
- Thumb stud for one-handed opening
- Belt clip
- Carabiner clip on back
- Liner Lock
- 3.75 inches closed
- 6.25 inches overall

C53BCP (black)
C53RCP (red)
3-in-1 Tool



- 400 series stainless steel drop point blade
- Zytel™ handle
- Large nail nick for one-handed opening
- Includes LED light, bottle cap lifter
- Liner lock
- 3 inches closed
- 4 inches overall

Distributed By:

EL66-08

C07CP
Skeleton Folder




- Titanium coated 400 series stainless steel spear point blade
- Powder coated handle
- Thumb stud for easy one-handed opening
- 4.25 in. closed
- 7 in. overall
- Belt clip
- Liner lock

C12CP
Folder




- Titanium coated 400 series stainless steel clip point blade
- Incised design handle
- Thumb stud for one-handed opening
- 4.5 in. closed
- 7.75 in. overall
- Belt clip
- Liner lock

C21CP
Z Frame Small

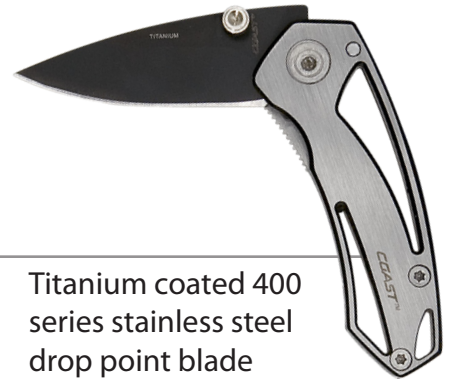

- Titanium coated 400 series stainless steel drop point blade
- Brushed steel open-frame handles
- Thumb stud for easy one-handed opening
- 2.5 in. closed
- 4.375 in. overall
- Liner lock

C22CP
Z Frame Large

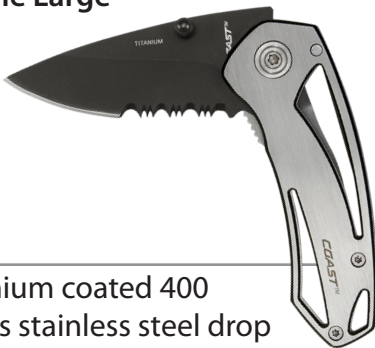

- Titanium coated 400 series stainless steel drop point blade w/partial serration
- Brushed steel open-frame handles
- 3.5 in closed
- 6 in. overall
- Belt clip
- Liner lock

C7401CP
LED Carabiner



- 400 series stainless steel drop point blade
- Zytel handle
- Thumb stud for easy one-handed opening
- Includes LED light (2 CR1220 incl.) & Carabiner clip
- 2.5 in. blade
- Liner lock

C22SGCP
Z Frame Large



- Titanium coated 400 series stainless steel drop point blade
- Brushed steel open-frame handles
- 3.5 in. closed
- 5.875 in. overall
- Belt clip
- Liner lock