


Features:

- Super Bright LEDs
- Flexible
- Connectible - Up To 15 Tubes
- Easy Installation
- Long Life - 50,000 Hours Avg.
- 1 Year Warranty
- Waterproof Main Body (IP64)

Applications:

- Interior Lighting
- Ceilings
- Shelves
- Cabinets
- Show cases
- Motor Homes
- RV's
- Boats
- Aviation

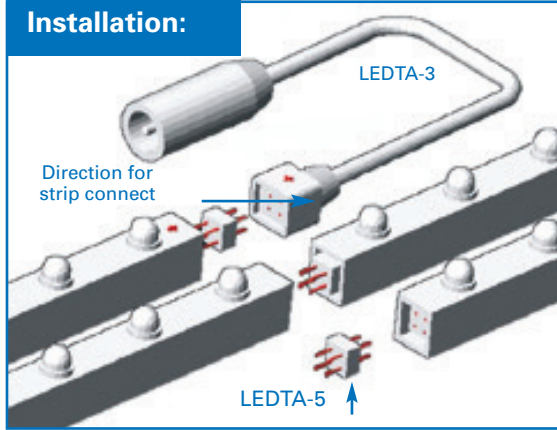

LED Tubing Specifications:

Part Number	Color	Size (Inches) (Length x Width x Height)	LED Quantity	Viewing Angle (°)
LEDT-B	Blue	11.81 x .31 x .41	15	120
LEDT-G	Green	11.81 x .31 x .41	15	120
LEDT-R	Red	11.81 x .31 x .41	15	120
LEDT-W	White	11.81 x .31 x .41	15	120
LEDT-Y	Amber	11.81 x .31 x .41	15	120
LEDT-RWB	Red, White, Blue	11.81 x .31 x .41	15	120

Single LED Intensity (mcd)				
Red	Green	Blue	White	Amber
6500	18000	5300	10100	7500

Voltage	Current	Maximum Tubes Per Supply
12VDC	50mA	15

Accessories Specifications:

Part Number	Description
LEDTA-1	Plastic Connector (Two Piece)
LEDTA-2	Connector Rotator (Requires LEDTA-1)
LEDTA-3	Power Supply Adapter
LEDTA-4	L Connector (Two Piece)
LEDTA-5	Electrical Connector
LEDTA-6	Power Supply & Adapter (12V, 2A)
LEDTA-7	3" Jumper Wire
LEDTA-8	6" Jumper Wire
LEDTA-9	12" Jumper Wire
LEDTA-10	24" Jumper Wire
LEDTA-11	36" Jumper Wire
LEDTA-12	24" Y Cable / 48" Jumper Wire

Operating Temperature Range	0 - 70°C
Storage Temperature Range	-20 - 90°C

NTE
ELECTRONICS, INC.

NTE Electronics, Inc.
44 Farrand Street,
Bloomfield, NJ 07003
www.nteinc.com

