

# Type ANF Automotive / Marine Limiter Fast Acting



www.optifuse.com (619) 593-5050

## Specifications:

- **Voltage Rating:** 32 VDC
- **Amperage Rating:** 40A, 50A, 60A, 80A, 100A, 125A, 130A, 150A, 175A, 180A, 200A, 225A, 250A, 275A, 300A, 400A

## • Construction:



- Body Material:** Bakelite
- Terminals:** Gold-plated
  - 40A ~ 80A – Brass
  - 100A ~ 400A – Copper Alloy

Time Characteristics	
% of Rated Current	Clearing Time
100%	Min 4h
250%	Max 300s

## Recommended Mounting:

- Optifuse Fuse Block BLC-09 to 200A
- Optifuse Fuse Block BLC-209 to 800A

## Mechanical Dimensions: Inches [mm]

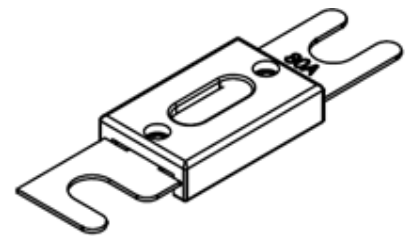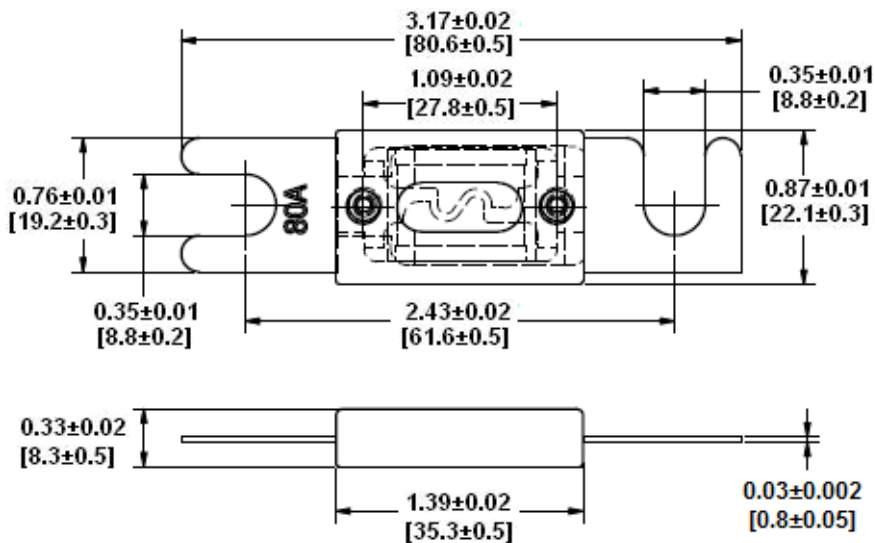

## Warning:



-Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.

-Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.

**Type ANF**  
**Automotive / Marine Limiter**  
**Fast Acting**



www.optifuse.com

(619) 593-5050

**Time Current Curve Graph**

