

Spacer plate - DP-UTT8 4 HV




3000781

<https://www.phoenixcontact.com/us/products/3000781>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.

Spacer plate, length: 69.9 mm, width: 2.6 mm, height: 33 mm, color: gray

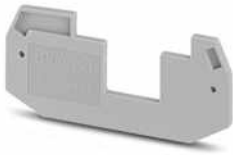

Commercial Data

Item number	3000781
Packing unit	1 pc
Minimum order quantity	50 pc
Note	Made to Order (non-returnable)
Sales Key	B01
Product Key	BE1Z1X
GTIN	4046356724654
Weight per Piece (including packing)	2.95 g
Weight per Piece (excluding packing)	2.95 g
Customs tariff number	39269097
Country of origin	CN

Spacer plate - DP-UTT8 4 HV



3000781

<https://www.phoenixcontact.com/us/products/3000781>

Technical Data

Product properties

Product type	End cover
--------------	-----------

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-60 °C ... 105 °C (max. short-term operating temperature RTI Elec.)
Ambient temperature (storage/transport)	-25 °C ... 60 °C (for a short time, not exceeding 24 h, -60 °C to +70 °C)
Ambient temperature (assembly)	-5 °C ... 70 °C
Ambient temperature (actuation)	-5 °C ... 70 °C
Permissible humidity (storage/transport)	30 % ... 70 %

Material specifications

Color	gray
Material	PA
Static insulating material application in cold	-60 °C
Temperature index of insulation material (DIN EN 60216-1 (VDE 0304-21))	130 °C
Relative insulation material temperature index (Elec., UL 746 B)	130 °C
Fire protection for rail vehicles (DIN EN 45545-2) R22	HL 1 - HL 3
Fire protection for rail vehicles (DIN EN 45545-2) R23	HL 1 - HL 3
Fire protection for rail vehicles (DIN EN 45545-2) R24	HL 1 - HL 3
Fire protection for rail vehicles (DIN EN 45545-2) R26	HL 1 - HL 3
Calorimetric heat release NFPA 130 (ASTM E 1354)	28 MJ/kg
Surface flammability NFPA 130 (ASTM E 162)	passed
Specific optical density of smoke NFPA 130 (ASTM E 662)	passed
Smoke gas toxicity NFPA 130 (SMP 800C)	passed

Dimensions

Width	2.6 mm
Height	33 mm
Length	69.9 mm

Spacer plate - DP-UTT8 4 HV



3000781

<https://www.phoenixcontact.com/us/products/3000781>

Classifications

ECLASS

ECLASS-9.0	27141133
ECLASS-10.0.1	27141133
ECLASS-11.0	27141133

ETIM

ETIM 8.0	EC000886
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

Spacer plate - DP-UTT8 4 HV



3000781

<https://www.phoenixcontact.com/us/products/3000781>

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Phoenix Contact 2023 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com