


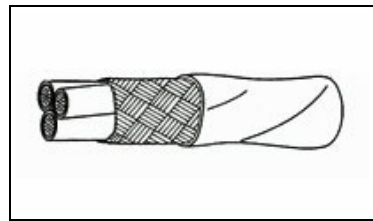

# 55FB1534-24-FLT3-0CS2173 Product Details

[Share](#) | [Print](#) | [Email](#)


## Spec 44, Spec 55 and Spec RCW Wire and Cable

Not EU RoHS or ELV Compliant

### Product Highlights:

- Cable Type = Spec 55F
- Wire Source = United States
- Cable Style = Primary
- Wire Size (AWG/CM) = 24 AWG
- Voltage Rating = 600 VAC

[View all Features](#)

### Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

**55FB1534-24-FLT3-0CS2173**

TE Internal Number: 147339-000  
✔ Active

[Add to My Part List](#)
[Request Sample](#)
[Find Similar Products](#)
[Buy Product](#)

## Documentation & Additional Information

**Product Drawings:**

- [THREE CONDUCTOR CABLE, SHIELDED, JACKETED, FILTER LI... \(PDF, English\)](#)

**Catalog Pages/Data Sheets:**

- None Available

**Product Specifications:**

- None Available

**Application Specifications:**

- None Available

**Instruction Sheets:**

- None Available

**CAD Files:**

- None Available

**Related Products:**

- [Tooling](#)

[List all Documents](#)

Feedback

## Product Features (Please use the Product Drawing for all design activity)

**Product Type Features:**

- [Cable Type](#) = Spec 55F
- [Cable Style](#) = Primary

**Electrical Characteristics:**

- Voltage Rating (VAC) = 600

**Body Features:**

- Wire Size (AWG/CM) = 24 AWG
- Cable Jacket Color = Black, Violet/Violet with Stripe Components
- Conductor Type = Silver-Plated Copper
- Wire Color = Violet/Violet with Striped Components
- Nominal Outside Diameter (mm [in]) = 2.13 [0.084]
- Shield Size = 38 AWG
- Shield Material = Tin-Plated Copper

**Configuration Features:**

- Number of Conductors = 3

**Industry Standards:**

- Government/Industry Qualification = Yes
- Government/Industry Part Number = M85485/12-24U3A
- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process

**Conditions for Usage:**

- Temperature Range (°C) = 150

**Operation/Application:**

- Application = General Purpose - Lightweight

**Packaging Features:**

- Wire Source = United States

**Other:**

- Brand = Raychem
- Comment = Product meets or exceeds all requirements of SAE AS85485/12 for 24 AWG, less identification.; Internal wire size 24 AWG meets or exceeds all requirements of SAE AS85485/10, less identification.

