


PRODUCT-DETAILS

MCB-10G

MCB-10G Contact Block

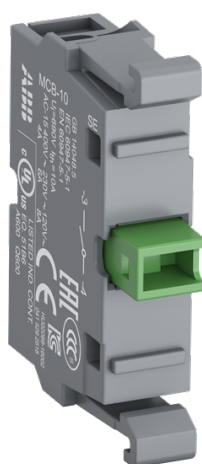

General Information

| | |
|-----------------------|-----------------------|
| Extended Product Type | MCB-10G |
| Product ID | 1SFA611610R101 |
| EAN | 7320500544372 |
| Catalog Description | MCB-10G Contact Block |
| Long Description | Modular contact block |

Ordering

| | |
|------------------------|---------------|
| E-Number (Finland) | 2315706 |
| E-Number (Sweden) | 3714007 |
| EAN | 7320500544372 |
| Minimum Order Quantity | 10 piece |
| Customs Tariff Number | 8536901000 |

Dimensions

| | |
|----------------------------|---------|
| Product Net Width | 0.01 m |
| Product Net Height | 0.044 m |
| Product Net Depth / Length | 0.028 m |
| Product Net Weight | 0.04 kg |

Container Information

| | |
|--------------------------------|---------------|
| Package Level 1 Units | bag 10 piece |
| Package Level 1 Width | 0.11 m |
| Package Level 1 Height | 0.01 m |
| Package Level 1 Depth / Length | 0.15 m |
| Package Level 1 Gross Weight | 0.4 kg |
| Package Level 1 EAN | 7320500307793 |

Environmental

| | |
|-------------|--|
| RoHS Status | Following EU Directive 2011/65/EU and Amendment 2015/863 July 22, 2019 |
|-------------|--|

Additional Information

| | |
|---|--|
| Accessory Type | Contact blocks and holders |
| Block | Gold plated contact block |
| Connection Type | Screw Clamp |
| Degree of Protection | Terminals IP20 |
| Function | Without holder |
| Illumination | Non-illuminated |
| Mechanical Durability | 10 million |
| Mounting Type | Front mounting |
| Number of Auxiliary Contacts NO | 1 |
| Product Main Type | MCB |
| Product Name | Contact Block |
| Product Range | Modular range |
| Product Type | MCB |
| Rated Frequency (f) | Supply Circuit 50 60 Hz |
| Rated Operational Current AC-15 (I _e) | (230 V AC) 6 A |
| Rated Operational Current DC-13 (I _e) | (24 V) 5 A (125 V) 1.1 A |
| RoHS Date | 0635 4 |
| Suitable For | MP1 MP2 MP3 MP4 MPD1 MPD2 MPD3 MPD4 MPD5 MPD11 MPD12 MPD13 MPD14 MPD15 MPD16 MPM1 MPM2 KP6 MPET3 MPEP3 MPEK3 MPET4 MPEP4 MPEK4 MPMT3 MPMT4 MPMP3 |

MPMP4
M2SS1
M2SS2
M2SS3
M2SS4
M2SS5
M2SS6
M3SS1
M3SS2
M3SS3
M3SS4
M3SS5
M3SS6
M3SS7
M3SS8
M3SSC1
M3SSC2
M3SSC3
M3SSC4
M3SSC5
M3SSC6
M3SSC7
M3SSC8
M2SSK1
M2SSK2
M2SSK3
M3SSK1
M3SSK2
M3SSK3
MTS1
MTS2
MTS3
MJS1
MJS2
MJS5
MJS6
MJS7
MJS8
MJS11
MJS12

Certificates and Declarations (Document Number)

| | |
|-----------------------------------|---------------------|
| CQC Certificate | CQC2005010304154103 |
| cULus Certificate | UL-E76003-20140513 |
| Data Sheet, Technical Information | 1SFC151007C02__ |
| Declaration of Conformity - CCC | 2020980305001528 |
| Declaration of Conformity - CE | 2CMT2015-005452 |
| DNV GL Certificate | E-14107 |
| Environmental Information | 1SFC151010D0201 |
| Instructions and Manuals | 1SFC151011M0201 |
| RoHS Information | 2CMT2015-005452 |

Classifications

| | |
|----------------------------|--|
| ETIM 4 | EC002024 - Accessories for control circuit devices |
| ETIM 5 | EC000041 - Auxiliary contact block |
| ETIM 6 | EC000041 - Auxiliary contact block |
| ETIM 7 | EC000041 - Auxiliary contact block |
| Object Classification Code | S |
| UNSPSC | 39121500 |

Categories

Low Voltage Products and Systems → Control Products → Pilot Devices → Modular Plastic Range

