


Disconnect  
switches  
Non-fusible

## Kits 16A – 3150A, 600V, 3 pole<sup>①</sup>

Each kit includes:  
1 three pole<sup>①</sup> switch  
1 handle  
1 shaft  
1 terminal lug kit

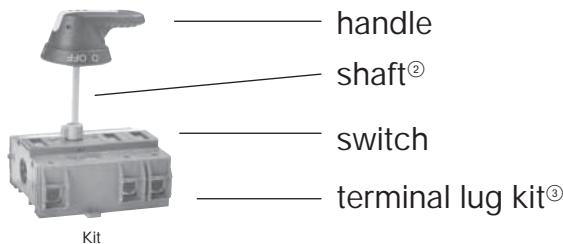

### Kits with base & DIN rail mounted switches and selector handles

UL general purpose amp rating	IEC AC21 amp rating	Maximum horsepower rating						Kit catalog number	List price
		Single phase		Three phase					
		120V	240V	200V – 208V	240V	480V	600V		
UL 508	16	1	2	3	5	10	10	OT16B2A1-180	\$ 100
	25	1.5	3	7.5	7.5	15	20	OT25B2A1-180	106
	40	2	5	10	10	20	25	OT32B2A1-180	110
UL 98	60	2	5	15	15	30	30	OT45B2A1-180	134
	80	2	5	20	20	40	40	OT63B2A1-180	154
	30	2	5	10	10	20	30	OT30B2A1-180	184
UL 98	60	3	7.5	20	20	40	40	OT60B2A1-180	209
	100	5	15	25	30	50	50	OT100B2A1-180	234

### Kits with base and/or DIN rail mounted switches and pistol handles

UL general purpose amp rating	IEC AC21 amp rating	Maximum horsepower rating						Kit catalog number	List price
		Single phase		Three phase					
		120V	240V	200V – 208V	240V	480V	600V		
UL 508	16	1	2	3	5	10	10	OT16B6-170	\$ 162
	25	1.5	3	7.5	7.5	15	20	OT25B6-170	168
	40	2	5	10	10	20	25	OT32B6-170	172
UL 98	60	2	5	15	15	30	30	OT45B6-170	196
	80	2	5	20	20	40	40	OT63B6-170	216
	30	2	5	10	10	20	30	OT30B6-170	246
UL 98	60	3	7.5	20	20	40	40	OT60B6-170	271
	100	5	15	25	30	50	50	OT100B6-170	296
	125	7.5	20	30	40	75	100	OT160B6-210	516
UL 98	200	—	—	60	75	150	200	OTK200B8-210	796
	400	—	—	100	125	250	350	OTK400B4-280	1736
	600	—	—	150	200	400	500	OT600B4-280	2706
UL 98	800	—	—	200	250	500	600	OT800B4-280	5066
	1200	—	—	—	—	—	—	OT1200B4-280	7926
	1600	—	—	—	—	—	—	OT1600M8-325	17,630
UL 98	2000	—	—	—	—	—	—	OT2000M8-325	19,430
	—	—	—	—	—	—	—	OT3150M8-325	21,130
	3150	—	—	—	—	—	—		

### 18 Kits with door mounted switches

UL general purpose amp rating	IEC AC21 amp rating	Maximum horsepower rating						Kit catalog number	List price
		Single phase		Three phase					
		120V	240V	200V – 208V	240V	480V	600V		
UL 508	16	1	2	3	5	10	10	OT16ET3S	\$ 98
	25	1.5	3	7.5	7.5	15	20	OT25ET3S	104
	40	2	5	10	10	20	25	OT32ET3S	108
UL 98	60	2	5	15	15	30	30	OT45ET3S	132
	80	2	5	20	20	40	40	OT63ET3S	152
	30	2	5	10	10	20	30	OT30ET3S	182
UL 98	60	3	7.5	20	20	40	40	OT60ET3S	207
	100	5	15	25	30	50	50	OT100ET3S	232
	30	2	5	10	10	20	30	OT30ET3P	254
UL 98	60	3	7.5	20	20	40	40	OT60ET3P	279
	100	5	15	25	30	50	50	OT100ET3P	304
	125	7.5	20	30	40	75	100	OT160ET3P	640

① Four poles are available — please reference accessories pages 18.12 & 18.21.

② Shaft is not required with door mounted switch, except OT160ET3.

③ 16A – 125A switches include standard integral terminal lugs.

④ Available as a kit using the standard base mount switch and a door mount bracket.