

**Discontinued**

**Typical Applications**

Electro-mechanical relays  
Thermal timers  
Solid state and hybrid time delay relays  
Solid state controls for liquid level sensing  
and other processes

**Description**

Screw terminals and captive self-lifting wire clips for reliable and easy wire insertion.\*  
Contrasting all-black bodies and accessories with nickel color terminals that facilitate easy wiring and/or trouble shooting.  
Integral molded barrier construction.  
Durable polycarbonate body. UL rated for flammability to 94V2 with high-voltage arc track characteristics.

Patented design assures positive connection that exceeds UL486 requirements for wire pull-out specifications, including heat and security standards. Back plate ultrasonically welded to body, eliminating need for additional panel insulation.

Choice of mountings: direct panel or track.  
Track: strong, lightweight aluminum; standard length 3 feet.  
Dielectric strength: 2000V.  
\*Combination slot/Phillips head screw available on request.

**Approvals**

UL Recognized File No. E48784.  
CSA Certified File No. LR28098.




**Ordering Information**

Octal Sockets for Cradle Relay

Catalog No.	Contact Arrangement
H50SL608	8 pin—2 pole double throw
H50SL611	11 pin—3 pole double throw

Blade Socket for Midget Power Relay


Catalog No.	Contact Arrangement
H50SL708	2 pole double throw
H50SL711	3 pole double throw
H50SL715	4 pole double throw

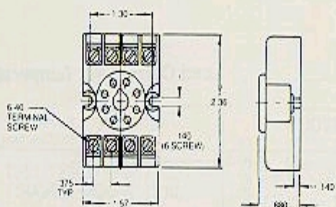

NOTE: SL608A is same as Model SL608 except Terminals: standard pan head 6-40 screw.


**H50SL608**

Industrial 8-pin octal socket. Rating: UL and CSA, 10 amperes, 300VAC. Wire sizes: up to #12 AWG. Terminals: pan head 6-40 screw.

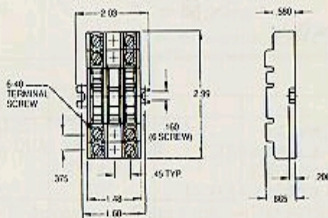


**H50SL708**

Industrial 8-pin blade type socket. Rating: UL, 15 amperes, 300VAC; CSA, 10 amperes, 300VAC. Wire sizes: up to #12 AWG. Terminals: pan head 6-40 screw.

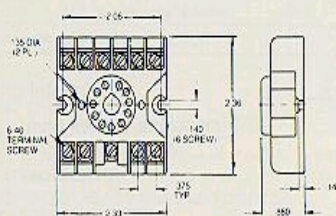


**H50SL611**

Industrial 11-pin magnol socket. Rating: UL and CSA, 10 amperes, 300VAC. Wire sizes: up to #12 AWG. Terminals: pan head 6-40 screw.

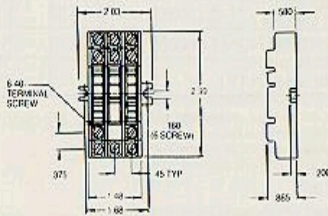

**H50SL711**

Industrial 11-pin blade type socket. Rating: UL, 15 amperes, 300VAC; CSA, 10 amperes. Wire sizes: up to #12 AWG. Terminals: pin head 6-40 screw.

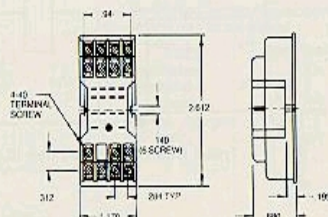

**H50SL715**

Industrial 14-pin blade type socket. Rating: UL and CSA, 5 amperes, 300VAC. Wire sizes: up to #14 AWG. Terminals: pan head 4-40 screw.

Back to [Catalog](#), or go to page: