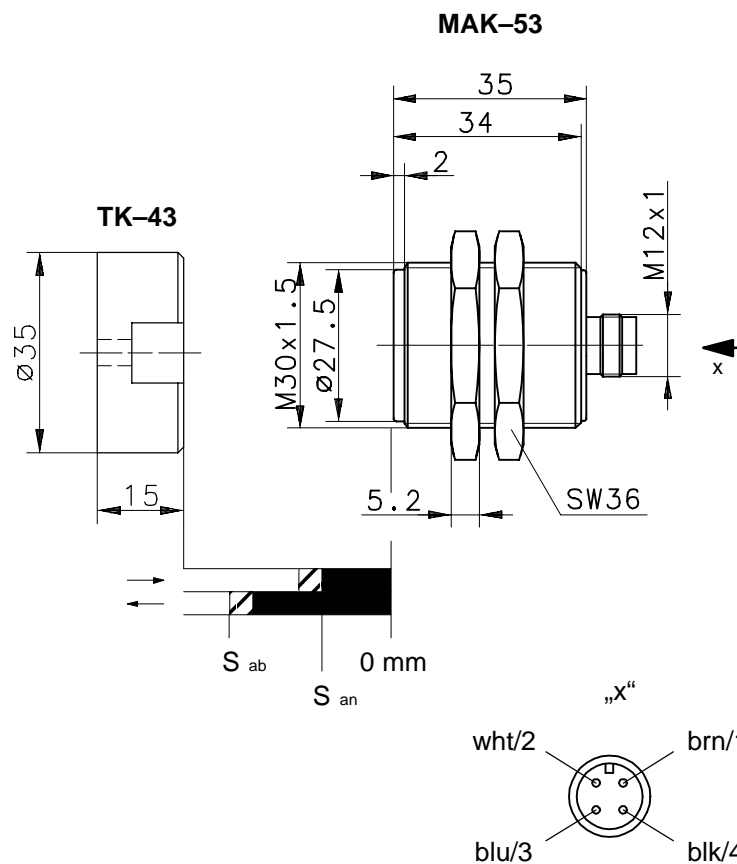
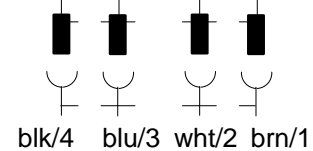
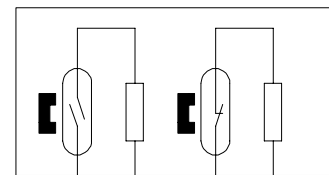


Type: **MAK-5336-STK**Art.-No.: **649.0653.313**

01.09.98/1080

**Comments:**

These coded magnetic systems offer manipulation-safe locking and can not be actuated with simple tools like depolarized magnets.

Wiring Diagram:

blk/4 blu/3 wht/2 brn/1

in use with

BERNSTEIN-junction-box

Magnetic System:

	TK-43-CD
S _{an} [mm]	3
S _{ab} [mm]	10

Technical Data

Max. Voltage	:	DC 30 V
Actuation	:	coded magnetic system of Type Tx-43-CD-xx preferredly 640.2043.023
Mech. Lifetime	:	3 x 10 ⁸ operations, depending on load
Repeat Accuracy	:	± 0,1 mm under same geometrical conditions at the same temperature
Temperature range	:	-5 °C ... +70 °C
Protection	:	IP 65 according to IEC 529, EN 60529 (only in fully snapped – in position with it's plugs)
Output function	:	N.O., N.C. combined

Mechanical Features

Housing	:	PA 6; encapsulated reed contact
Connection	:	plug M12x1
Application	:	monitoring system of Type MÜZ-x02/xxx optional assembly position