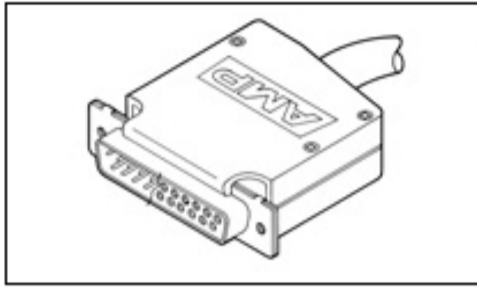


205730-3 Product Details

[Live Product Chat](#)


205730-3

Cable Clamps

[Not EU RoHS or ELV Compliant \(Find RoHS Compliant Alternates\)](#)

Product Highlights:

- Backshell/Cable Clamp
- Cable Clamp Type = Clam Shell
- Straight(180°)/45° Cable Exit Angle
- Cable Insulation Diameter = 8.13 mm
- Shell Size = 2

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

TE Internal Number: 205730-3



Superseded

[Add to My Part List](#)

[Request Sample](#)

[Find Similar Products](#)

[Buy Product](#)

[Search for Replacement Parts](#)

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- [AMPLIMITE SUBMINATURE D TYPE CONNECTORS](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- [Cable Clamp Assemblies for AMPLIMITE HD-20 and HD-22...](#) (PDF, English)

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Backshell/Cable Clamp
- [Cable Clamp Type](#) = Clam Shell
- [Shell Size](#) = 2
- [Shielded](#) = No
- [Screws and Retainer Clips](#) = Without
- [Grommets](#) = Without
- Thread Size = 6-32
- Product Series = HD-20 (Solder Cup)
- Clam Shell Length = Standard
- Comment = Each part is individually bulk packed for multiple kit orders.; All parts are packaged unassembled.

Body Related Features:

- [Cable Exit Angle](#) = Straight(180°)/45°
- [Cable Insulation Diameter \(mm \[in\]\)](#) = 8.13 [0.320]
- Cable Clamp Material = Thermoplastic
- Shield Plating = None

Industry Standards:

- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process

Packaging Related Features:

- [Packaging Method](#) = Bulk

Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)