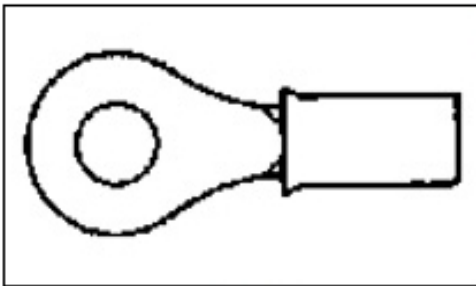


## 320634 Product Details

 [Live Product Chat](#)
**320634**

TE Internal Number: 320634

 **Active**
 [View 3D PDF](#)

### Ring and Spade Terminal

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- Terminal Shape = Ring Tongue
- Receptacle Style = Straight
- Body Style = PIDG
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

[View all Features](#)
 [Add to My Part List](#)
 [Request Sample](#)
 [Find Similar Products](#)
 [Buy Product](#)

#### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [TERMINAL, PIDG, RING TONGUE, WIRE SIZE: 12-10 \(PDF, English\)](#)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- [Pre-Insulated Diamond Grip \(PIDG\) Terminals, Splices... \(PDF, English\)](#)

#### Instruction Sheets:

- None Available

#### CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing \(DXF, Version E\)](#)
- [3D Model \(IGES, Version E\)](#)
- [3D Model \(STEP, Version E\)](#)

[List all Documents](#)

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Terminal Shape](#) = Ring Tongue
- [Receptacle Style](#) = Straight
- [Body Style](#) = PIDG
- [Barrel Type](#) = Closed Barrel
- [Wire/Cable Type](#) = Regular Wire
- [Insulation](#) = Yes
- [Insulation Support](#) = Insulation Support
- [Insulation Diameter \(mm \[in\]\)](#) = 3.81-5.84 [.150-.230]
- Stud Size = 6 [M3.5]
- [Stud Diameter \(mm \[in\]\)](#) = 3.68 [0.145]
- [Shape](#) = RING-041
- [Heavy Duty](#) = No
- [Material](#) = Copper
- [Finish](#) = Tin
- Tongue Material Thickness (mm [in]) = 1.02 [0.040]
- Color = Yellow
- Insulation Material = Nylon

#### Electrical Characteristics:

- Voltage (VAC) = 300

#### Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 3.00-6.00<sup>2</sup> [12-10]
- Wire Range (CMA) = 5,180 - 13,100
- Length (mm [in]) = 24.21 [0.953]
- Insulation Sleeve Material = Copper

#### Industry Standards:

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Packaging Related Features:

- [Packaging Method](#) = Loose Piece

#### Other:

- Brand = AMP

 [Provide Website Feedback](#) | [Need Help?](#)