


FST-41B-5 Product Details


Live Product Chat US Only
 8:30am - 5pm ET, Mon - Fri

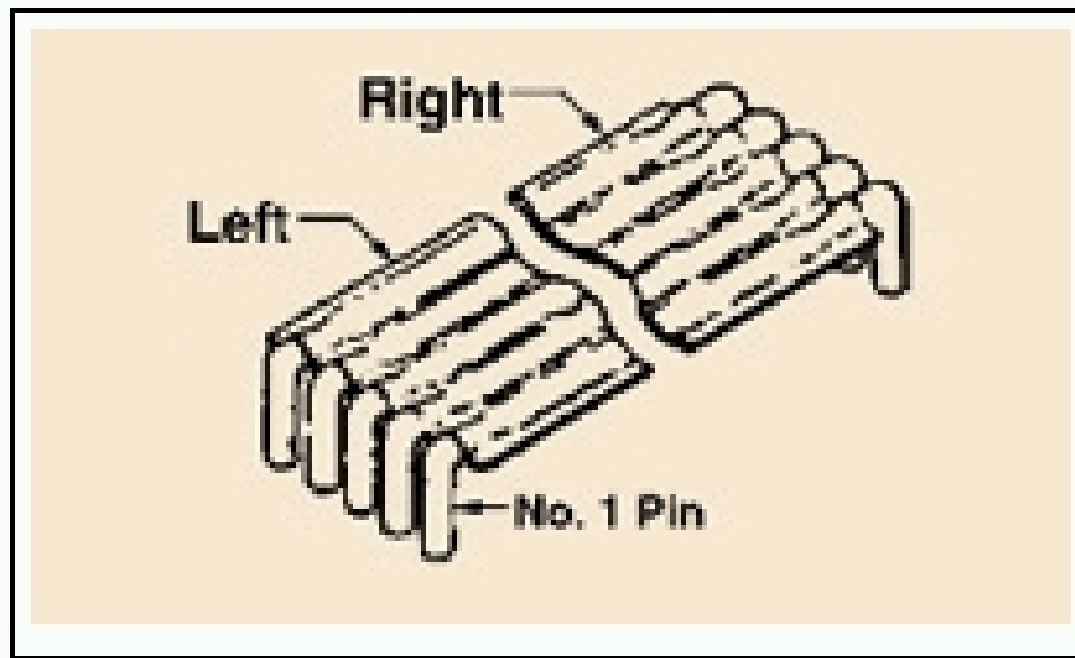

FLEXSTRIP® Jumpers


[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- 3.81 mm Centerline
- Teflon Insulation Material
- Insulation Length = 25.40 mm
- Pin Arrangement (Left) = B
- Pin Arrangement (Right) = B

[View all Features](#) |
 [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

FST-41B-5
(4-1437191-8)
 TE Part Number: 4-1437191-8
 [Active](#)
 [Add to Part List](#)

Documentation & Additional Information

Product Drawings:

- [FLEXSTRIP PIN CONFIGURATIONS, GENERIC \(PDF, English\)](#)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Product View](#)
- [Product View](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Insulation Material](#) = Teflon
- [Number of Conductors](#) = 5

Electrical Characteristics:

- Current Rating (Amps.) = 3.5
- Impedance (Ω) = 132
- Voltage Rating (VAC) = 300

Body Related Features:

- [Centerline \(mm \[in\]\)](#) = 3.81 [0.150]
- [Insulation Length \(mm \[in\]\)](#) = 25.40 [1.000]

Configuration Related Features:

- [Pin Arrangement \(Left\)](#) = B
- [Pin Arrangement \(Right\)](#) = B

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not reviewed for lead free solder process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Operating Temperature (°C [°F]) = -40 - +150 [-40 - +302]

Other:

- Brand = Tyco Electronics