


## 521435-1 Product Details

**Live Product Chat** US Only  
8:30am - 5pm ET, Mon - Fri

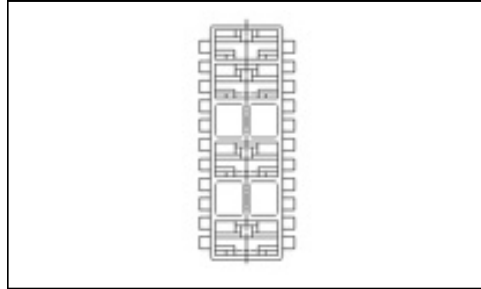

**521435-1**

✓ [Active](#)

### Positive Lock Connectors

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

#### Product Highlights:

- Receptacle Housing
- Tab Fit = 6.35 mm
- Line = Mark III
- Receptacle Style = Straight
- Loose Piece

[View all Features](#) | [Find Similar Products](#)

### Quick Links

[Check Pricing & Availability](#)  
[Search for Tooling](#)  
[Product Feature Selector](#)  
[Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [HOUSING, RECEPT, POSITIVE-LOCK, MKIII, 6.35 \[.250\] S...](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Receptacle Housing
- [Tab Fit \(mm \[in\]\)](#) = 6.35 [.250]
- [Receptacle Style](#) = Straight
- Number of Positions = 6
- [Color](#) = Blue
- [Material](#) = Nylon 6/6
- [Keyed](#) = No
- Polarization = No

#### Body Related Features:

- [Position Keyed](#) = None
- [Centerline \(mm \[in\]\)](#) = 5.00 [0.197]
- Flammability Rating = UL 94V-0

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Packaging Related Features:

- [Packaging Method](#) = Loose Piece

#### Other:

- [Line](#) = Mark III
- Brand = AMP