


737439 -2 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

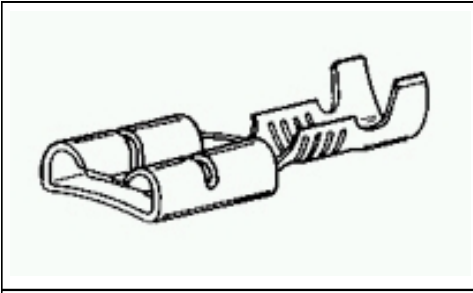

737439 -2

[Active](#)

FASTON Uninsulated Receptacles & Housings

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Receptacle
- ? Tab Fit = 6.35 x 0.81 mm
- ? Board Mount = No
- ? Receptacle Style = Straight
- ? Insulation Support

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [RECEPTACULO FASTON 6,35](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Receptacle
- ? [Tab Fit \(mm \[in\]\)](#) = 6.35 x 0.81 [.250 x .032]
- ? [Receptacle Style](#) = Straight
- ? [Insulation Support](#) = Insulation Support
- ? [Wire/Cable Type](#) = Stranded
- ? [Insulation Diameter \(mm \[in\]\)](#) = 2.36 -3.30 [.093 -.130]
- ? [Insertion Force](#) = Low
- ? [Material](#) = Brass
- ? [Finish](#) = Tin
- ? [Crimp Type](#) = "F"
- ? CSA Certified = Yes

Mechanical Attachment:

- ? [Board Mount](#) = No

Body Related Features:

- ? [Weld Tab](#) = Without
- ? [Wire Range \(mm \[AWG\]\)](#) = 0.30 -0.90² [22-18]
- ? UL Rating = Listed

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ? [Packaging Method](#) = Strip

Other:

- ? [For Hermetic Header Tab](#) = No
- ? [Line](#) = Premier
- ? Brand = AMP