

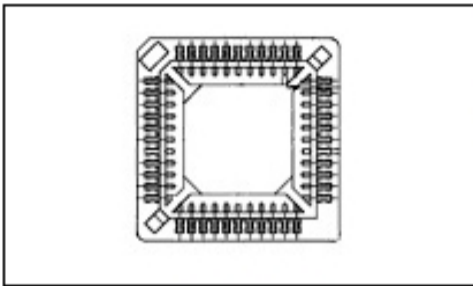


Our commitment. Your advantage.

Search

[Products](#) [Documentation](#) [Resources](#) [My Account](#) [Customer Support](#)[Home](#) > [Products](#) > [By Type](#) > [Socket/Card Products](#) > [Product Feature Selector](#) > Product Details

822499-3 Product Details

[Live Product Chat](#)**822499-3**

PLCC Sockets

[Not EU RoHS or ELV Compliant \(Find RoHS Compliant Alternates\)](#)

Product Highlights:

- Socket Type = PLCC - Standard
- 20 Positions
- 1.27 mm Centerline
- Low Insertion Force
- Surface Mount Contact Termination Type

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

TE Internal Number: 822499-3

**Superseded**[Add to My Part List](#)[Request Sample](#)[Find Similar Products](#)[Buy Product](#)[Search for Replacement Parts](#)

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Product Photo](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Number of Positions](#) = 20
- [Insertion Force](#) = Low
- [Polarizing Pin](#) = Without
- Package Configuration = Rectangular

Electrical Characteristics:

- Current Rating (Amps.) = 1
- Contact Resistance (mΩ) = 20
- Voltage Rating (VAC) = 250

Body Related Features:

- Socket Type = PLCC - Standard
- Centerline (mm [in]) = 1.27 [0.050]

Contact Related Features:

- [Contact Termination Type](#) = Surface Mount
- Contact Base Material = Phosphor Bronze
- Contact Plating, Mating Area, Material = Tin-Lead

Housing Related Features:

- Housing Material = Thermoplastic
- Housing Flammability Rating = UL 94V-0

Configuration Related Features:

- [Height Above PC Board \(mm \[in\]\)](#) = 4.60 [0.181]

Industry Standards:

- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Reflow solder capable to 245°C

Packaging Related Features:

- [Packaging Method](#) = Tube

Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)