


## 1487588-1 Product Details

Have a Question?

Chat with a Product Information Specialist

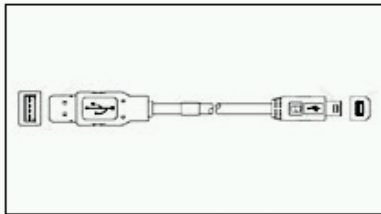

1487588-1

TE Internal Number: 1487588-1

Active

### Cable Assemblies

[Converted to EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- Industry Standard Cable Assembly Category
- Cable Assembly Type = Universal Serial Bus (Standard)
- Input/Output (I/O) Application
- Assembly Type = USB 4 Position Plug, Type A to Type B
- Double Ended Configuration

[View all Features](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

#### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [CABLE ASSEMBLY, USB A TYPE TO USB B TYPE](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- Cable Assembly Category = Industry Standard
- Cable Assembly Type = Universal Serial Bus (Standard)
- [Assembly Type](#) = USB 4 Position Plug, Type A to Type B
- [Color](#) = White
- [Wire Size \(mm<sup>2</sup> \[AWG\]\)](#) = 2/28,2/24
- Keyed = No

#### Mechanical Attachment:

- Configuration = Double Ended

#### Electrical Characteristics:

- Shielded = Yes

#### Body Related Features:

- [Number of Positions](#) = 4
- [Length \(M \[ft\]\)](#) = 2.00 [6.562]
- [Equalized](#) = Yes

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Converted to comply with RoHS directive

#### Operation/Application:

- [Application](#) = Input/Output (I/O)

#### Other:

- Brand = AMP

BOOKMARK

### Corporate Information

[Who We Are](#)  
[Investors](#)  
[News Room](#)  
[Supplier Portal](#)  
[Careers](#)

### Quick Links

[Check Distributor Inventory](#)  
[Cross Reference](#)  
[Find Documents & Drawings](#)  
[Product Compliance Support Center](#)  
[Site Map](#)

 
### Customer Support

[Email or Chat with Us](#)  
[Find a Phone Number](#)  
[Search Knowledge Base](#)  
[Manage Your Account](#)

### Sign up for our eNewsletter

Enter your email address

### Follow Us On:



Visit Us On:

