


281839-4 Product Details

Have a Question?

Chat with a Product Information Specialist

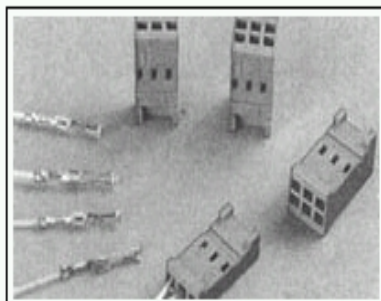

281839-4

TE Internal Number: 281839-4

Active

[View 3D PDF](#)

.100 AMPMODU Headers, Housings & Contacts

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Connector
- Housing
- Connector Style = Receptacle
- Contact Type = Receptacle
- 2.54 mm Centerline

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [DOUBLE ROW HOUSING FOR HE 13-14 COSI CONTACT \(PDF, English\)](#)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- [MODULAR HEADERS AND PLUGS ACCORDING TO IEC 60603-8 S... \(PDF, French\)](#)

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: [\(CAD Format & Compression Information\)](#)

- [2D Drawing \(DXF, Version C\)](#)
- [3D Model \(IGES, Version C\)](#)
- [3D Model \(STEP, Version C\)](#)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Connector
- Connector Type = Housing
- [Termination Method to Wire/Cable](#) = Crimp, Insulation Displacement Crimp (IDC)
- [Mating Connector Lock](#) = Without
- Mating Polarization = Without
- [Connector Series](#) = HE13 / HE14
- [Keyed](#) = No

Body Related Features:

- Centerline (mm [in]) = 2.54 [0.100]
- Row-to-Row Spacing (mm [in]) = 2.54 [0.100]
- [Number of Positions](#) = 4
- [Number of Rows](#) = 2

Contact Related Features:

- Contact Type = Receptacle

Housing Related Features:

- Connector Style = Receptacle
- [Housing Color](#) = Blue
- UL Flammability Rating = UL 94V-0
- Housing Material = PBT - GF

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- Packaging Method = Loose Piece

Other:

- Brand = AMP

BOOKMARK

Corporate Information

- [Who We Are](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat with Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

Sign up for our eNewsletter

Enter your email address

Follow Us On:



Visit Us On:

