


## 8-328998-1 Product Details

Have a Question?

Chat with a Product Information Specialist

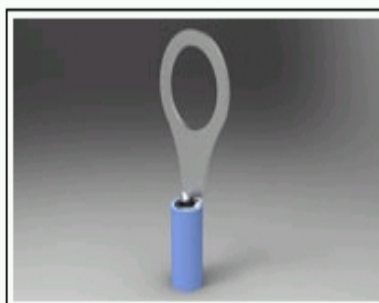

8-328998-1

### Ring and Spade Tongue Terminals

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

**Product Highlights:**

- Terminal Shape = Ring Tongue
- Receptacle Style = Straight
- Body Style = PIDG
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

[View all Features](#)

TE Internal Number: 8-328998-1

**Active**

[View 3D PDF](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

**Quick Links**

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

### Documentation & Additional Information

**Product Drawings:**

- [WIRE TERMINAL, P.I.D.G. RING TONGUE WIRE SIZE: 16 14 \(PDF, English\)](#)

**Catalog Pages/Data Sheets:**

- None Available

**Product Specifications:**

- None Available

**Application Specifications:**

- [Pre-Insulated Diamond Grip \(PIDG\) Terminals, Splices... \(PDF, English\)](#)

**Instruction Sheets:**

- None Available

**CAD Files:** [\(CAD Format & Compression Information\)](#)

- [2D Drawing \(DXF, Version J\)](#)
- [3D Model \(IGES, Version J\)](#)
- [3D Model \(STEP, Version J\)](#)

**Additional Information:**

- [Product Line Information](#)

**Related Products:**

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

**Product Type Features:**

- [Terminal Shape](#) = Ring Tongue
- [Receptacle Style](#) = Straight
- [Body Style](#) = PIDG
- [Barrel Type](#) = Closed Barrel
- [Wire/Cable Type](#) = Regular Wire
- [Insulation](#) = Yes
- [Insulation Support](#) = Insulation Support
- [Insulation Diameter \(mm \[in\]\)](#) = 4.32 [.170] Max.
- [Stud Diameter \(mm \[in\]\)](#) = 8.33 [0.328]
- Stud Size = 5/16 [M8]
- [Shape](#) = RING-041
- [Heavy Duty](#) = No
- [Material](#) = Copper
- [Finish](#) = Tin
- Tongue Material Thickness (mm [in]) = 0.79 [0.031]
- Color = Blue
- Insulation Material = Nylon

**Electrical Characteristics:**

- Voltage (VAC) = 300

**Body Related Features:**

- [Wire Range \(mm \[AWG\]\)](#) = 1.25-2.00<sup>2</sup> [16-14]
- Wire Range (CMA) = 2,050 - 5,180

**Industry Standards:**

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

**Packaging Related Features:**

- [Packaging Method](#) = Loose Piece
- Packaging Quantity = 100/Box

**Other:**

- Brand = AMP

BOOKMARK

**Corporate Information**

- [Who We Are](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

**Quick Links**

- [Check Distributor Inventory](#)
- [Cross Reference](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

 
**Customer Support**

- [Email or Chat with Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

**Sign up for our eNewsletter**

Enter your email address

**Follow Us On:**



Visit Us On:

