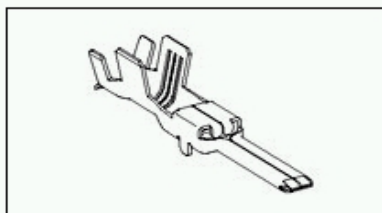


1326029-7 Product Details

[Share](#) [Print](#) [Email](#)


1326029-7

TE Internal Number: 1326029-7

 [Active](#)

Timer Contacts

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Contact
- Contact Type = Tab
- Wire Range = 1.25-2.00² [16-14] mm [AWG]
- Accepts Wire Insulation Diameter, Range = 1.89 - 2.70 mm
- No Single Wire Sealing

[View all Features](#)

[Add to My Part List](#)  [Request Sample](#)  [Find Similar Products](#)  [Buy Product](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [2.8mm BLADE, UNSEALED](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [2.8 mm Terminal System \(Sealed and Unsealed\)](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Contact
- Mating Area Interface Dimensions (mm [in]) = 2.79 x 0.81 [.110 x .032]
- [Wire/Cable Type](#) = Regular Wire
- Insulation Support = With

Body Features:

- [Wire Range \(mm \[AWG\]\)](#) = 1.25-2.00² [16-14]
- Single Wire Sealing System = No
- [Tab Type](#) = Wire Crimp

Contact Features:

- Contact Type = Tab
- [Contact Base Material](#) = Copper Alloy
- [Contact Plating, Mating Area, Material](#) = Pre-Tin

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- [Accepts Wire Insulation Diameter, Range \(mm \[in\]\)](#) = 1.89 - 2.70 [0.074 - 0.106]
- [Applies To](#) = Wire/Cable

Packaging Features:

- [Packaging Method](#) = Strip
- Packaging Quantity = 3,000/Reel

Other:

- GET 0.64 Connector System = No
- Brand = Tyco Electronics
- Comment = Reverse Reel

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

