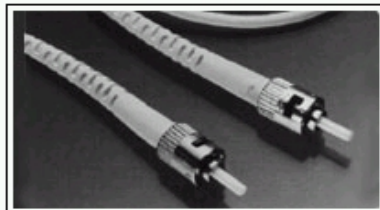


5349573-4 Product Details

[Share](#) [Print](#) [Email](#)


5349573-4

TE Internal Number: 5349573-4

 [Active](#)

Fiber Optic Cable Assemblies

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Cable Assembly
- ST Fiber Optic Cable Connector Type
- Fiber Type = 62.5/125 Micron
- Cable Assembly Type = ST-Style (2.5mm Bayonet) to ST-Style (2.5mm Bayonet)
- Multimode

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#)
 [Request Sample](#)
 [Find Similar Products](#)
 [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [FOMM62,5 LEAD 2,5S ST - ST](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Cable Assembly
- [Fiber Optic Cable Connector Type](#) = ST
- Cable Assembly Type = ST-Style (2.5mm Bayonet) to ST-Style (2.5mm Bayonet)
- Cable Type = Simplex

Termination Features:

- [Fiber Type \(Micron\)](#) = 62.5/125
- [Mode](#) = Multimode
- Insertion Loss (dB) = 0.30

Body Features:

- Cable Diameter (mm [in]) = 2.40 [.094]
- Number of Fibers = 1
- Cable Color = Orange
- Length (M [ft]) = 4.00 [13.12]
- Ferrule Material = Ceramic

Contact Features:

- Boot Body Style - Left = Standard
- Boot Color - Left = Black
- Boot Body Style - Right = Standard
- Boot Color - Right = Black
- Fibre Channel = No

Housing Features:

- Flammability Rating Type = Low Smoke Zero Halogen (LSZH)

Configuration Features:

- Cable Buffering = Tight Buffered Easy Strip
- Connector(s) Exit Angle to Connector(s) Exit Angle = 180° to 180°

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- Brand = AMP

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

