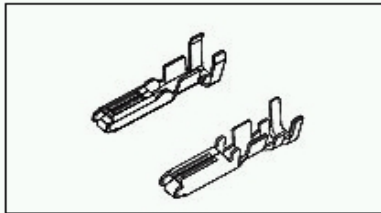


## 776129-2 Product Details

 [Share](#)
 [Print](#)
 [Email](#)


776129-2

TE Internal Number: 776129-2

 [Active](#)

### MULTILOCK Connectors and Contacts

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- Contact
- Contact Type = Receptacle
- Applies To Wire/Cable
- Wire/Cable Type = Discrete Wire
- Wire Range = 2.00-2.15<sup>2</sup> [14] mm [AWG]

[View all Features](#)

 [Add to My Part List](#)
 [Request Sample](#)
 [Find Similar Products](#)
 [Buy Product](#)

#### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [.070 SERIES RECEPTACLE CONTACT \(PDF, English\)](#)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Contact
- [Wire/Cable Type](#) = Discrete Wire
- [Body Shape](#) = D
- [Proprietary Name](#) = MULTILOCK
- [Product Series](#) = 070

#### Body Features:

- [Wire Range \(mm \[AWG\]\)](#) = 2.00-2.15<sup>2</sup> [14]

#### Contact Features:

- [Contact Type](#) = Receptacle
- [Contact Base Material](#) = Phosphor Bronze
- [Contact Plating, Mating Area, Material](#) = Tin

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not reviewed for lead free solder process
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

#### Conditions for Usage:

- [Applies To](#) = Wire/Cable
- [Accepts Wire Insulation Diameter, Range \(mm \[in\]\)](#) = 2.20 - 2.39 [0.0866 - 0.094]

#### Packaging Features:

- [Packaging Method](#) = Strip

#### Other:

- [Brand](#) = AMP

### Corporate Information

[Who We Are](#)  
[Investors](#)  
[News Room](#)  
[Supplier Portal](#)  
[Careers](#)

### Quick Links

[Check Distributor Inventory](#)  
[Cross Reference](#)  
[Find Documents & Drawings](#)  
[Product Compliance Support Center](#)  
[Site Map](#)

### Customer Support

[Email or Chat With Us](#)  
[Find a Phone Number](#)  
[Search Knowledge Base](#)  
[Manage your Account](#)

### Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address 