


**AMP PLASTI-GRIP**

Kabelschuhe  
und Verbinder,  
gerippt,  
Trichtereinführung  
(Fortsetzung)

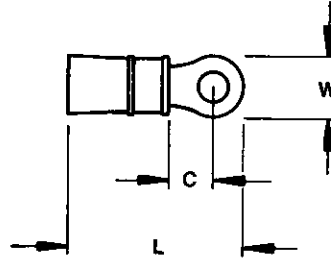

Bolzen Bolt M	Bolzenloch Stud Hole (mm)	Abmessungen/Dimensions (mm)			Bestell-Nummer Part Number
		W	L	C	
2,5	3,0	6,4	17,3	4,3	342141-1
3,0-3,5	3,7	6,4	17,3	4,3	342142-1
4,0	4,3	8,7	21,4	7,1	342143-1
5,0	5,3	8,7	21,1	7,1	342144-1
6,0	6,7	11,9	27,0	11,1	342145-1
8,0	8,3	11,9	27,0	11,1	342146-1
9,5	9,9	13,5	30,6	13,9	342147-1

Leiterquerschnittsbereich:  
1,0-2,6 mm<sup>2</sup>

AWG:  
16-14 (blau)

Isolierungsdurchmesser:  
max. 4,3 mm

Genehmigung:  
C.E.G.B.

Handzangen:  
Best.-Nr. 525691-0 oder  
Best.-Nr. 47387-7

**AMP PLASTI-GRIP**

Terminals  
and Splices,  
Ribbed,  
Funnel Entry  
(continued)


Wire Size Range:  
1.0-2.6 mm<sup>2</sup>

AWG:  
16-14 (blue)


Insulation Diameter:  
4.3 mm max.

Approval:  
C.E.G.B.

Hand Tools:  
Part No. 525691-0 or  
Part No. 47387-7

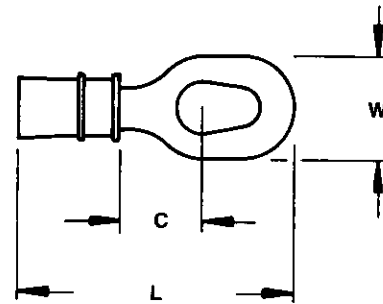

Bolzen Bolt M	Bolzenloch Stud Hole (mm)	Abmessungen/Dimensions (mm)			Bestell-Nummer Part Number
		W	L	C	
3,5	3,7-5,0	8,3	24,4	7,1	342130-1
4,0-5,0					

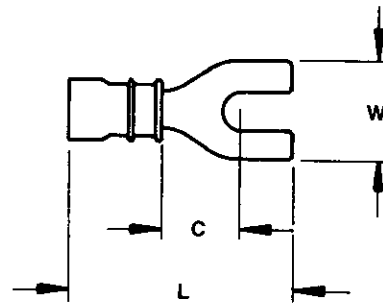

Bolzen Bolt M	Bolzenloch Stud Hole (mm)	Abmessungen/Dimensions (mm)			Bestell-Nummer Part Number
		W	L	C	
3,0-3,5	3,7	9,5	22,6	7,9	342157-1
4,0	4,3	9,5	22,6	7,9	342158-1
5,0	5,0	9,8	22,6	7,9	342159-1