
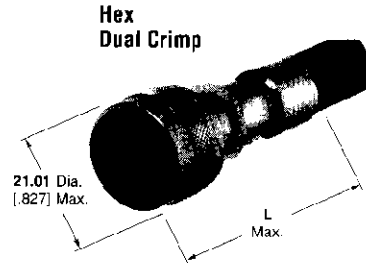
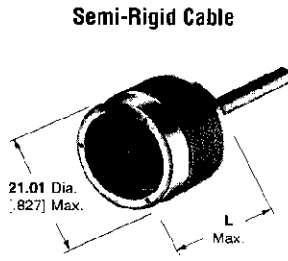


N Series Connectors, 50 Ohm (Continued)

Plugs

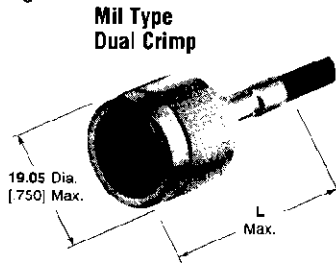

RG/U Cable	Termination Type	Body Plating	M39012/ Military No. and/ or Comments	Dim. L	Integral Die Hand Tool	Hex Across Flats		Part No.
						Center	Braid	
58, 58A, 58B, 58C	O Crimp	Nickel	Knurl Collar	42.85 1.687	220045-2	—	—	1-225661-2*
	O Crimp	Silver	Knurl Collar	42.85 1.687	220045-2	—	—	225361-1*
58A, 58C	Hex Crimp	Nickel	Knurl Collar	39.40 1.550	58436-1**	1.73 .068	5.41 .213	415232-2
223, 55, 55A, 55B	O Crimp	Nickel	Knurl Collar	42.85 1.687	220045-2	—	—	1-225661-3*
	O Crimp	Silver	Knurl Collar	42.85 1.687	220045-2	—	—	225361-2*
142, 142A, 142B, 400	O Crimp	Nickel	Knurl Collar	42.85 1.687	220045-2	—	—	1-225661-5*
	O Crimp	Silver	Knurl Collar	42.85 1.687	220045-2	—	—	225361-4*
142, 142A, 142B	Hex Crimp	Nickel	Hex Collar	39.40 1.550	58436-1**	1.73 .068	5.41 .213	415232-3
			Knurl Collar	39.40 1.550	58436-1**	1.73 .068	5.41 .213	415232-4
115A, Belden 89880, 9880	O Crimp	Nickel	Knurl Collar	42.85 1.687	220015-1	—	—	225092-8
Belden 9880	Hex Crimp	Nickel	Hex Collar	39.40 1.550	58485-1**	2.54 .100	10.90 .429	415232-9
			Knurl Collar	39.40 1.550	58485-1**	2.54 .100	10.90 .429	1-415232-0
402 Semi Rigid (.141)	Solder	Nickel	Knurl Collar	24.6 .970	—	—	—	1057088-1
405 Semi Rigid (.085)	Solder	Nickel	Knurl Collar	24.6 .970	—	—	—	1057094-1
8, 8A, 213	O Crimp	Nickel	Knurl Collar	42.85 1.687	220015-1	—	—	1-227086-0
			Knurl Collar	42.85 1.687	220015-1	—	—	225661-2
			01B0007 Knurl Collar	42.85 1.687	220015-1	—	—	51692-2
8, 213	Hex Crimp	Nickel	Hex Collar	39.40 1.550	58485-1**	2.54 .100	10.90 .429	415232-5
			Knurl Collar	39.40 1.550	58436-1**	2.54 .100	10.90 .429	415232-6
11, 11A, 216	O Crimp	Silver	01B0013 Knurl Collar	42.85 1.687	220015-1	—	—	51692-4
Belden 9292	O Crimp	Nickel	—	47.22 1.859	220015-1	—	—	1-225662-8
393	Hex Crimp	Nickel	Hex Collar	39.40 1.550	58485-1**	2.54 .100	10.90 .429	1-415232-1
Belden 8214	O Crimp	Nickel	Knurl Collar	42.85 1.687	220015-1	—	—	1-225661-6
9, 9A, 9B, 214	O Crimp	Nickel	Knurl Collar	42.85 1.687	220015-1	—	—	225661-1
			01B0008 Knurl Collar	42.85 1.687	220015-1	—	—	51692-1
			Knurl Collar	42.85 1.687	220015-1	—	—	1-227086-1
9, 214	Hex Crimp	Nickel	Hex Collar	39.40 1.550	58485-1**	2.54 .100	10.90 .429	415232-7
			Knurl Collar	39.40 1.550	58485-1**	2.54 .100	10.90 .429	415232-8

*Hand Tool 69710-1, with Die Insert 220062-1, is available to terminate these connectors. The 626 Pneumatic tool system can also be used.