



**BNC Connectors, 50 Ohm (Continued)**

**Plugs, Crimp (Continued)**

**Single Crimp**

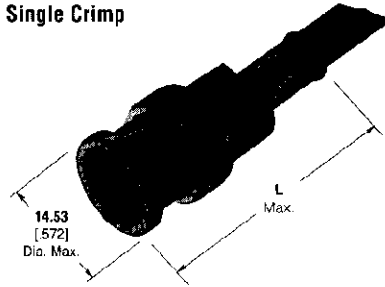

**Hex and O Crimp**

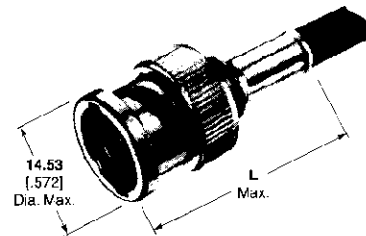

RG/U Cable	Termination Type	Center Contact Plating	Body Plating	Dielectric	Style	Dim. L	CERTI-CRIMP Hand Tool with Integral Die	Interchangeable Dies for PRO-CRIMPER Hand Tool 354940-1 or PRO-CRIMPER Adapter 579304-1	Interchangeable Dies for Hand Tool 69710-1 & 626 Pneu.	Part No. Head 318161-1
58, 58A, 58B, 58C	Hex Crimp	Gold	Nickel	Polyethylene	Commercial	33.53 1.320	—	58436-1 <sup>2</sup>	—	221128-1 <sup>3</sup>
	O Crimp	Gold	Nickel	Polyethylene	Commercial	27.69 1.090	220187-1	58435-1 <sup>1</sup>	220217-1	227079-5
	O Crimp	Silver	Nickel	Polyethylene	Commercial	27.69 1.090	220187-1	58435-1 <sup>1</sup>	220217-1	227079-9
	O Crimp	Gold	Nickel	Polyethylene	Economy	27.69 1.090	—	58558-1	—	414852-1
	O Crimp	Gold	Nickel	Polyethylene	Economy	27.69 1.090	—	—	—	414915-1 <sup>4,5</sup>
	O Crimp	Gold	Nickel	TEFLON	Mil Type	33.74 1.328	69478-1	220189-3	69727	225395-1
	O Crimp	Gold	Silver	TEFLON	Mil Type	33.74 1.328	69478-1	220189-3	69727	2-331350-1
141, 141A, 303	Single Crimp	Gold	Silver	TEFLON	Mil Type	33.33 1.312	69140-1	—	69223-1	2-329444-1
	O Crimp	Gold	Nickel	TEFLON	Mil Type	30.18 1.188	69473-1	220189-3	69727	225395-5
Belden 88240, Berk-Tek BTDC-53, Comm Scope 2135	Hex Crimp	Gold	Nickel	Polyethylene	Commercial	33.53 1.320	—	58436-1 <sup>2</sup>	—	1-221128-0
	O Crimp	Gold	Nickel	Polyethylene	Commercial	33.33 1.312	220187-1	58435-1 <sup>1</sup>	220217-1	4-227079-3
	O Crimp	Gold	Nickel	TEFLON	Mil Type	33.33 1.312	69478-1	220189-3	69727	4-225395-2
223, 55, 55A, 553	O Crimp	Gold	Nickel	Polyethylene	Commercial	27.69 1.280	220187-1	58435-1 <sup>1</sup>	220217-1	227079-6
	O Crimp	Gold	Nickel	TEFLON	Mil Type	43.64 1.718	69478-1	220189-3	69727	225395-3
	Single Crimp	Gold	Silver	TEFLON	Mil Type	33.33 1.312	69140-2	—	69424	2-329444-2
	O Crimp	Gold	Nickel	Polyethylene	Commercial	27.69 1.090	220187-1	58435-1 <sup>1</sup>	220217-1	6-227079-1
142, 142A, 142B, 400	O Crimp	Gold	Nickel	TEFLON	Mil Type	30.18 1.188	69478-1	220189-3	69727	225395-6
	O Crimp	Gold	Silver	TEFLON	Mil Type	30.18 1.188	69478-1	220189-3	69727	2-331350-9
	Single Crimp	Gold	Silver	TEFLON	Mil Type	33.33 1.312	69331-1	—	69429-1	2-330358-2

Consult AMP for recommended crimp tooling.

<sup>1</sup>Order AMP PRO-CRIMPER Coaxial "O" Crimp Hand Tool assembly 58433-1, which includes dies 58435-1.

<sup>2</sup>Order AMP PRO-CRIMPER Coaxial Hex Crimp Hand Tool assembly 58433-2, which includes dies 58436-1.

<sup>3</sup>Bulk packaged.

<sup>4</sup>Kit includes connector subassembly and ferrule only, center contact part no. 414724-2 supplied separately on strip.

<sup>5</sup>Terminate with Amp-o-lectric terminating machine 220152-1 with applicator.