



BNC Connectors, 50 Ohm (Continued)

Plugs, Crimp (Continued)

Single Crimp

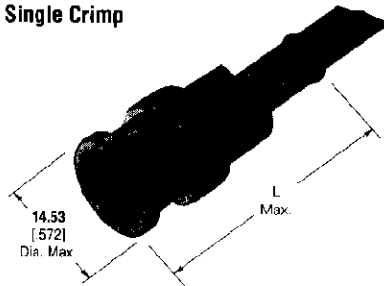

Hex and O Crimp

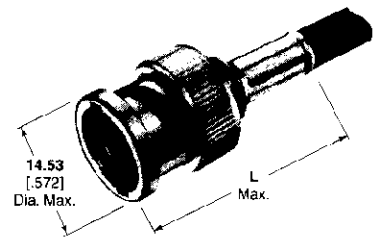

RG/U Cable	Termination Type	Center Contact Plating	Body Plating	Dielectric	Style	Dim. L	CERTI-CRIMP Hand Tool with Integral Die	Interchangeable Dies for PRO-CRIMPER Hand Tool 354940-1 or PRO-CRIMPER Adapter 679304-1	Interchangeable Dies for Hand Tool 69710-1 & 626 Pneu. Head 318161-1	Part No.
124, 140, 210, 62, 62A, 62B, 59, 59A, 59B, Belden 9291, 9209, 9269	Hex Crimp	Gold	Nickel	Polyethylene	Commercial	33.53 1.320	—	58436-1*	—	1-221128-1
	O Crimp	Gold	Nickel	Polyethylene	Commercial	27.69 1.090	220187-2	58435-1*	220217-2	227079-7
	O Crimp	Silver	Nickel	Polyethylene	Commercial	27.69 1.090	220187-2	58435-1*	220217-2	1-227079-1
	O Crimp	Gold	Nickel	Polyethylene	Economy	27.69 1.090	—	58558-1	—	414852-2
	O Crimp	Gold	Nickel	Polyethylene	Economy	27.69 1.090	—	—	—	414915-2**
	O Crimp	Gold	Nickel	TEFLON	Mil Type	30.18 1.183	69477-1	58537-1	—	225395-2
	O Crimp	Gold	Silver	TEFLON	Mil Type	30.18 1.183	69477-1	—	69659-1	331350
	Single Crimp	Gold	Silver	TEFLON	Mil Type	33.33 1.312	69141-1	—	—	2-329445-1
302, Belden 88241, 89269, Hi-Temp 62A, Times PL62, Berk-Tek, BTDC-59 BTDC-62	Hex Crimp	Gold	Nickel	Polyethylene	Commercial	33.53 1.320	—	58436-1*	—	1-221128-1
	O Crimp	Gold	Nickel	Polyethylene	Commercial	33.33 1.312	220187-2	58435-1*	220217-2	4-227079-9
	O Crimp	Gold	Nickel	TEFLON	Mil Type	34.14 1.344	69477-1	58537-1	69669-1	4-225395-1
Hi-Temp 59, Times PL59, PLF59 (20 AWG C.C.)	O Crimp	Gold	Nickel	Polyethylene	Commercial	33.33 1.312	—	58537-1	—	5-227079-3
Belden 9104, 9240, 9112, 9167, 9259, 9266, Times FM-59	Hex Crimp	Gold	Nickel	Polyethylene	Commercial	33.53 1.320	—	58436-1*	—	1-221128-7
	O Crimp	Gold	Nickel	Polyethylene	Commercial	27.69 1.090	220187-2	58537-1	—	1-227079-3
	O Crimp	Gold	Nickel	TEFLON	Mil Type	30.94 1.218	69477-1	58537-1	69669-1	2-225395-0
Belden 9248, 9114	O Crimp	Gold	Nickel	Polyethylene	Commercial	27.69 1.090	220247-1	58539-1	—	3-227079-0
Belden 8281, 9141, 9231, Western Electric 724, 728, 3049	Hex Crimp	Gold	Nickel	Polyethylene	Commercial	33.53 1.320	—	58436-2	—	1-221128-2
	O Crimp	Gold	Nickel	Polyethylene	Commercial	31.75 1.250	220043-1	58538-1	220088-1	5-227079-8
	O Crimp	Gold	Silver	TEFLON	Mil Type	38.10 1.500	220043-1	58538-1	220088-1	4-331350-0
	Single Crimp	Gold	Silver	Polypropylene	Mil Type	41.50 1.634	69652	—	220000	330878
6, 8A, 213	O Crimp	Gold	Silver	TEFLON	Mil Type	27.31 1.075	220015-1	—	—	225886-1
1", 11A	O Crimp	Gold	Silver	TEFLON	Mil Type	47.63 1.875	220015-1	—	—	225886-4
Belden 9914, Times FM-8	O Crimp	Gold	Silver	TEFLON	Mil Type	47.63 1.875	220015-1	—	—	225886-7
Alpha 9847, Belden 8213, 9292	O Crimp	Gold	Silver	TEFLON	Mil Type	47.63 1.875	220015-1	—	—	225886-5
9, 9A, 9B, 214	O Crimp	Gold	Silver	TEFLON	Mil Type	52.38 2.062	220015-1	—	—	225886-1

*Order AMP PRO-CRIMPER Coaxial "O" Crimp Hand Tool assembly 58433-1, which includes dies 58435-1.

**Order AMP PRO-CRIMPER Coaxial Hex Crimp Hand Tool assembly 58433-2, which includes dies 58436-1.

AMP PRO-CRIMPER II Hand Tool Frame without dies Part No. 354940-1

*Kit includes connector sub assembly and ferrule only, center contact part no. 414724-4 supplied separately on strip.

**Terminate with Amp-o-lectric terminating machine 220152-1 with applicator.