

J1/J4 Type A Right-Angle Female Connector

Materials and Finish


Glass filled polyester housing, gray,
UL94 V-0 rated.
Phosphor-bronze signal contacts and
shields
Contact area 0.8µm Au
over 1.3µm Ni
ACTION PIN contact 0.5µm Sn/Pb
over 1.3 µm Ni.

CompactPCI specified coding keys
are available for this connector as
shown on page 44.

Enhanced electrical performance is
attained through the use of pre-
attached upper ground return shield.

- 110 signal contacts
- Length 49.9mm
- Integrated pre-alignment and polarizing guide lug
- Daughter Card applications

Technical documents see pg 82.

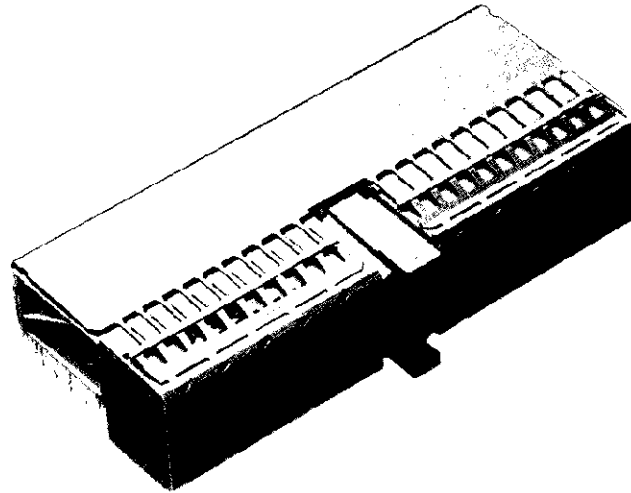

Connector Type	CompactPCI Designation	Number of Signal Contacts	Part Number
A	J1, J4	110	352C68-1

