


J2/J5 Type B Right-Angle Female Connector

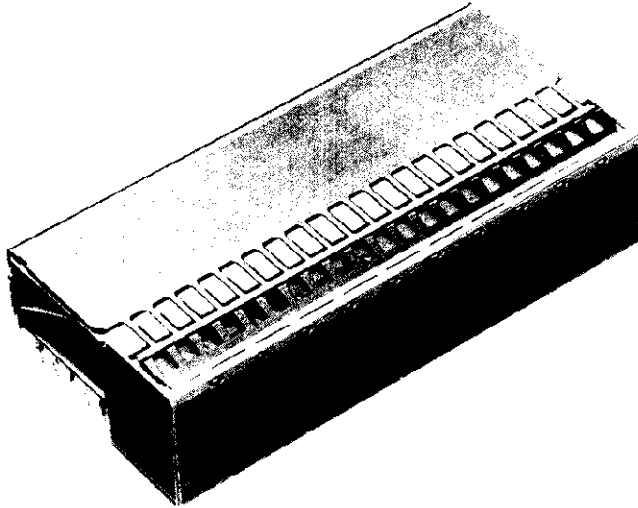

Materials and Finish

Glass filled polyester housing, gray, UL94 V-0 rated.
 Phosphor-bronze signal contacts and shields
 Contact area 0.8µm Au
 over 1.3µm Ni
 ACTION PIN contact 0.5µm Sn/Pb
 over 1.3 µm Ni.

Enhanced electrical performance is attained through the use of pre-attached upper ground return shields.

- 110 signal contacts
- Length 43.9mm
- Daughter Card applications

Technical documents see pg 82.

Connector Type	CompactPCI Designation	Number of Signal Contacts	Part Number
B (22)	J2, J5	110	352152-1
B (22)	J5 (Telephony)	110	88836-1*

*Used when Tip & Ring I/O feature is used in the J5 connector. (Upper shield not included).

