


## P4 Type A Vertical Male Feed-Thru

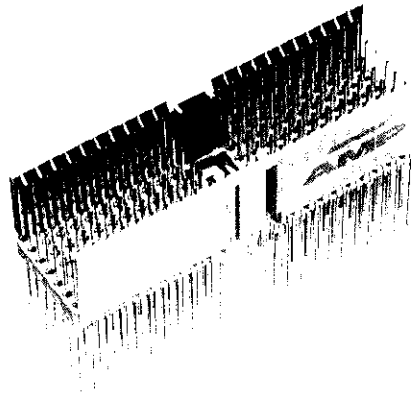

### Materials and Finish

Glass filled polyester housing gray,  
UL94 V-0 rated  
Phosphor-bronze signal contacts  
Contact area 0.8µm Au over 1.3µm Ni  
ACTION PIN contact 0.5µm Sn/Pb  
over 1.3 µm Ni

CompactPCI specified coding keys  
are available for this connector as  
shown on the CompactPCI table on  
page 44.

### 5 & 2 Row Configuration



This configuration accommodates  
the upper ground return shield fea-  
ture on the mating female connector  
by providing contacts in rows z & f  
in addition to the five rows of signal  
pins.

Mylar tail guides are available for  
feed thru posts to aid assembly to  
the board.


- 110 signal contacts
- Length 49.9mm
- Integrated pre-alignment
- Mid-plane applications

Technical documents see pg 82.


Connector Type	Compact PCI Designation	Number of Signal Contacts	Part Number
A	P4	110	188578-1
A	P4	110	352495-1

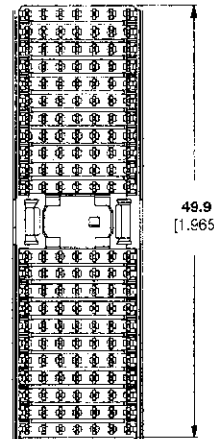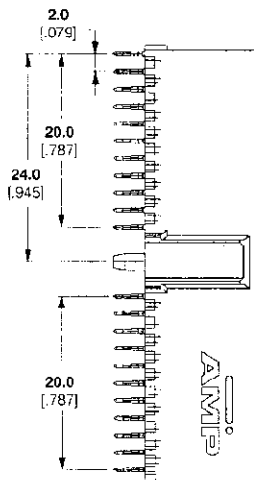


### Contact Layout

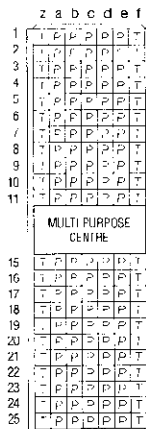

188578-1

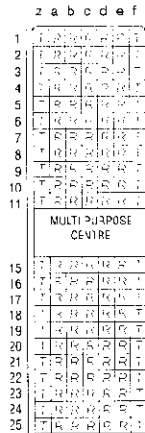

352495-1

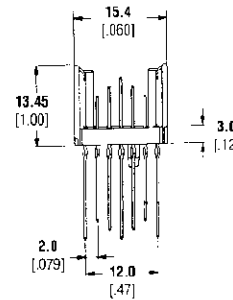

### CONTACT DIMENSIONS

