


Flexible Conduit Connectors

Flexible conduit Connectors are designed for connecting 9.53mm (3/8") and 12.70mm (1/2") trade size flexible conduit - Greenfield types - to electrical panels or boxes. They provide fast, reliable connectors in a variety of applications.

Connecting flexible conduit using AMP NETCONNECT straight-thru or right-angle connectors is easy. A connector is simply screwed onto the conduit until it stops, then the connector is snapped into the knockout hole of a panel or box. No screw clamps are needed to hold the conduit in the connector, and no locknut is needed to retain the connector in the panel or box.

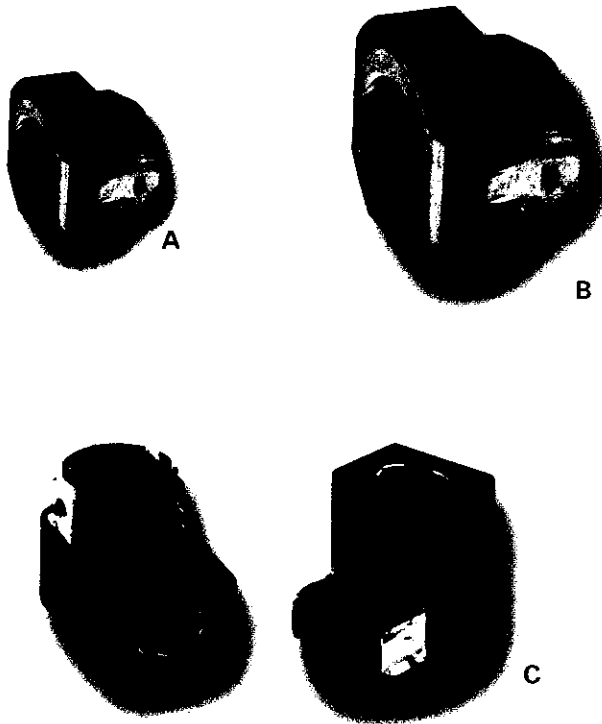

Product Facts

- :: Rated 125° C (257° F)
- :: Fully grounded
- :: UL Listed for use on 9.53mm (3/8") flexible conduit. UL file number: E60108
- :: Recognized under the Component Program of Underwriters Laboratories, Inc. for use on 12.70mm (1/2") flexible conduit. UL file number: E60108
- :: Designed to UL performance Standard 514B
- :: Certified by Canadian Standards Association (CSA), report numbers: LR42374-1 and LR38656-1



Description	Flexible Conduit Size mm (in)	Figure	Part Number
Straight-Thru Connectors	9.53 (0.375)	A	207370-1
	12.70 (0.500)	B	207373-1*
Right-Angle Connectors	9.53 (0.375)	C	207508-1

* Not UL Listed.