
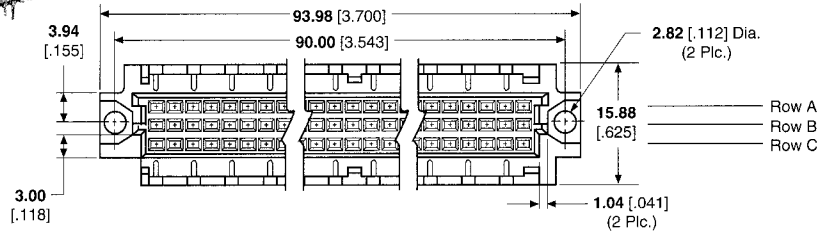


Enhanced Type C Vertical Receptacle Assemblies with Solder Leads and ACTION PIN Leads


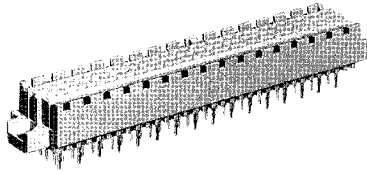


Material


- Housing** — Glass filled polymer
- Receptacle Contacts** — Copper alloy
- Ground Contacts** — Copper alloy

Related Product Data

- Electrical/Mechanical Data** — Page 11
- Mateable Connector** — Page 25
- PC Board Hole Layout** — Page 59
- ACTION PIN Contacts** — Pages 70, 71

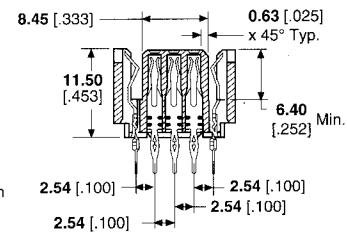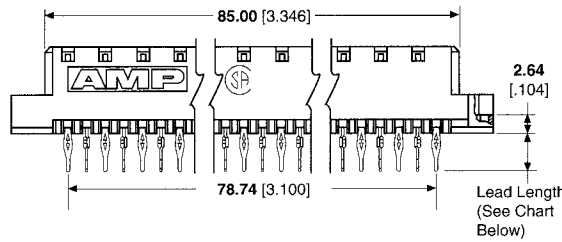

ACTION PIN Contacts

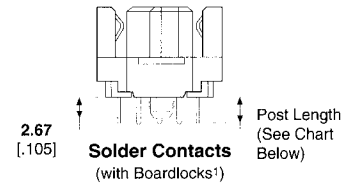

Standard Size (for 1.57 [.062] Min. PC Board Thickness)

| Number of Positions | Rows Loaded | DIN Levels | Solder Contacts | | ACTION PIN Contacts* |
|---------------------|-------------|------------|-------------------------|-------------------------|-------------------------|
| | | | 3.30 [.130] Lead Length | 4.57 [.180] Lead Length | 4.83 [.190] Lead Length |
| 96 | A,B,C | II | 536152-5 | 536153-5 | 650992-5 |
| | | | 536154-5 ¹ | 536155-5 ¹ | — |

¹ With Boardlocks

* Connectors with ACTION PIN contacts on this page are toolless (flat rock).

Type C Assemblies