

**Four-Row Right Angle Pin Assemblies with Solder Posts**

**4x32 (128) Positions**

**Material**

**Housing** — Glass filled polymer  
**Contacts** — Copper alloy

**Related Product Data**

**DIN Performance Levels** — Page 6

**Performance Specifications** —  
Page 7

**Mateable Connectors** — Page 33

**PC Board Hole Layout** — Page 60


**Technical Documents** — Page 74:

DIN Specification 41612

IEC Specification 60603-2

Application Specification 114-9014

Instruction Sheet 408-6784

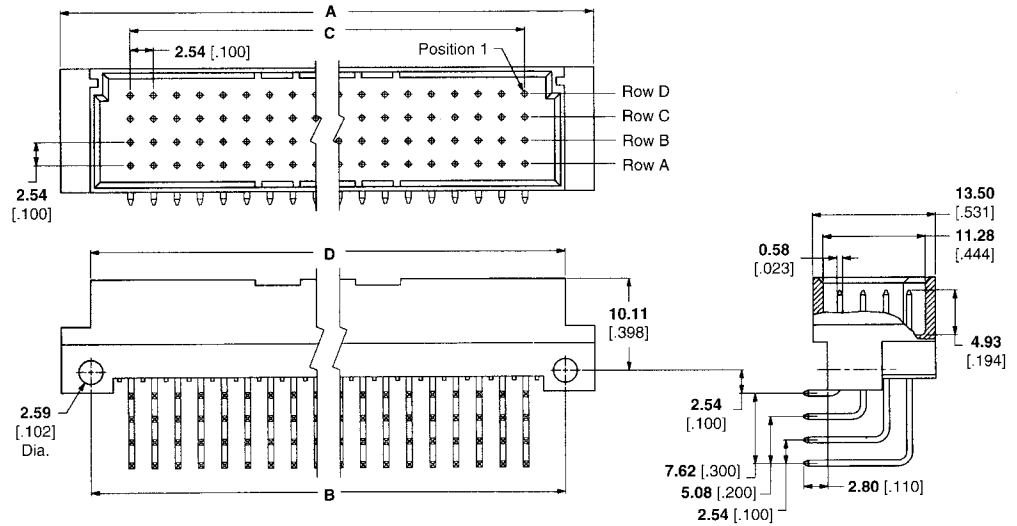

Number of Positions	Rows Loaded	Dimensions				DIN Level	Part Number
		A	B	C	D		
128	A,B,C,D	93.90 3.697	88.90 3.500	78.74 3.100	87.50 3.445	II	106739-4

Four-Row Assemblies