


**Product Details for FSN -64A -6**

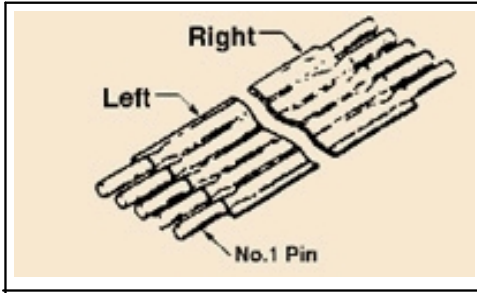

**FSN -64A -6**

Tyco Part Number: 8 - 1437151 - 5

**Superseded**  
[Search for Replacement Parts](#)

**FLEXSTRIP® Jumpers**

[Not ELV or RoHS Compliant](#) ([Find RoHS Compliant Alternates](#))

**Product Highlights:**

- ? 1.91 mm Centerline
- ? Nomex Insulation Material
- ? Insulation Length = 101.60 mm
- ? Pin Arrangement (Left) = A
- ? Pin Arrangement (Right) = A

[View all Features](#)

**Quick Links**

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

**Documentation & Additional Information**

**Product Drawings:**

- ? [FLEXSTRIP PIN CONFIGURATIONS, GENERIC](#) (PDF, English)

**Catalog Pages/Data Sheets:**

- ? None Available

**Product Specifications:**

- ? None Available

**Application Specifications:**

- ? None Available

**Instruction Sheets:**

- ? None Available

**CAD Files:**

- ? None Available

**Additional Information:**

- ? [Product Line Information](#)

**Additional Product Images:**

- ? [Product View](#)
- ? [Product View](#)

**Related Products:**

- ? [Tooling](#)

[List all Documents](#)

**Product Features** (Please use the Product Drawing for all design activity)

**Product Type Features:**

- ? [Insulation Material](#) = Nomex
- ? [Number of Conductors](#) = 6

**Mechanical Attachment:**

- ? Impedance (?) = 110

**Electrical Characteristics:**

- ? Current Rating (Amps.) = 2
- ? Voltage Rating (VAC) = 200

**Body Related Features:**

- ? [Centerline \(mm \[in\]\)](#) = 1.91 [0.075]
- ? [Insulation Length \(mm \[in\]\)](#) = 101.60 [4.000]

**Configuration Related Features:**

- ? [Pin Arrangement \(Left\)](#) = A
- ? [Pin Arrangement \(Right\)](#) = A

**Industry Standards:**

- ? [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- ? [Lead Free Solder Processes](#) = Not reviewed for lead free solder process

**Conditions for Usage:**

- ? Operating Temperature (°C [°F]) = -40 – +125 [-40 – +257]

**Other:**

- ? Brand = Tyco Electronics