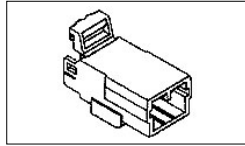


[My Cart](#) | [My Part Lists](#) | [Sign In/Register](#)English [\(Change\)](#)

Search by Keyword or Part #

**174929-2 Product Details****Have a Question?**

Chat with a Product Information Specialist

**174929-2**

TE Internal Number: 174929-2



Active

[View 3D PDF](#)**MULTILOCK Connectors and Contacts**[Always ELV Compliant \(Statement of Compliance\)](#)**Product Highlights:**

- Connector
- Housing
- Connector Style = Receptacle
- Accepts Contact Gender = Tab
- Receptacle Configuration = 070

[View all Features](#)**Quick Links**

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#)[Request Sample](#)[Find Similar Products](#)[Buy Product](#)**Documentation & Additional Information****Product Drawings:**

- [070 SERIES MULTI-LOCK I/O CONNECTOR 4POSITION CAP HO...](#) (PDF, Japanese)

**Catalog Pages/Data Sheets:**

- None Available

**Product Specifications:**

- [JAPANESE](#) (PDF, English)
- [070 SERIES MULTI LOCK I/O CONNECTOR\(MLC\)](#) (PDF, Japanese)

**Application Specifications:**

- None Available

**Instruction Sheets:**

- None Available

**CAD Files:** ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version C2)
- [3D Model](#) (IGES, Version C2)
- [3D Model](#) (STEP, Version C2)

[List all Documents](#)**Additional Information:**

- [Product Line Information](#)

**Related Products:**

- [Tooling](#)

**Product Features (Please use the Product Drawing for all design activity)****Product Type Features:**

- [Product Type](#) = Connector
- Connector Type = Housing
- [Receptacle Configuration](#) = 070
- Wire/Cable Type = Discrete Wire
- [Mating Connector Lock](#) = With
- [Mating Connector Lock Type](#) = Hinge Lock
- [Mating Connector Number Positions](#) = 4
- [Keyed](#) = No
- Proprietary Name = MULTILOCK
- Product Series = 070

**Mechanical Attachment:**

- [Panel Mount Retention](#) = Without

**Body Related Features:**

- [Number of Rows](#) = 1
- [Number of Positions](#) = 4

**Contact Related Features:**

- Accepts Contact Gender = Tab

**Housing Related Features:**

- Connector Style = Receptacle
- [Housing Color](#) = Black
- Housing Material = PBT - GF
- UL Flammability Rating = UL 94-HB

**Industry Standards:**

- [RoHS/ELV Compliance](#) = ELV compliant
- [Lead Free Solder Processes](#) = Not reviewed for lead free solder process
- RoHS/ELV Compliance History = Always was ELV compliant

**Conditions for Usage:**

- [Applies To](#) = Wire

**Other:**

- Brand = AMP

[Bookmark and Share](#)**Corporate Information**[Who We Are](#)[Investors](#)[News Room](#)[Supplier Portal](#)[Careers](#)**Quick Links**[Check Distributor Inventory](#)[Cross Reference](#)[Find Documents & Drawings](#)[Product Compliance Support Center](#)[Site Map](#)**Customer Support**[Email or Chat with Us](#)[Find a Phone Number](#)[Search Knowledge Base](#)[Manage Your Account](#)**Sign up for our eNewsletter**

Enter your email address

**Follow Us On:**

Visit Us On:

[Provide Website Feedback](#)