


## 208334-5 Product Details

Share | Print | Email

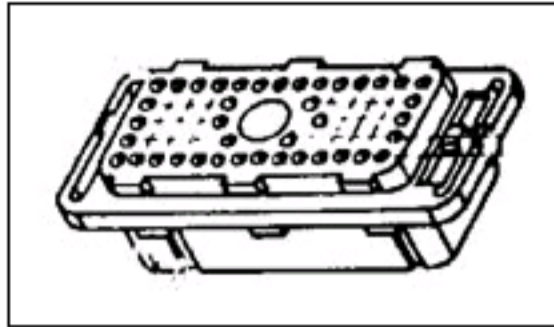

208334-5

TE Internal Number: 208334-5

Active

View 3D PDF

5mm (.197") Centerline, 600 V, 14 A max. (Metrimate)

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

**Product Highlights:**

- Housing
- Housing
- Rectangular Connector Configuration
- 62 Positions
- Plug

[View all Features](#)

**Quick Links**

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) | Request Sample | Find Similar Products | Buy Product

**Documentation & Additional Information**

**Product Drawings:**

- [PLUG ASSEMBLY, 62 POSN, WITH MALE CENTER FASTENER, M...](#) (PDF, English)

**Catalog Pages/Data Sheets:**

- None Available

**Product Specifications:**

- None Available

**Application Specifications:**

- None Available

**Instruction Sheets:**

- None Available

**CAD Files:** ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version P)
- [3D Model](#) (IGES, Version P)
- [3D Model](#) (STEP, Version P)

**Additional Information:**

- [Product Line Information](#)

**Additional Product Images:**

- [Recommended Panel Cutout](#)

**Related Products:**

- [Tooling](#)

[List all Documents](#)

**Product Features** (Please use the Product Drawing for all design activity)

**Product Type Features:**

- [Product Type](#) = Housing
- Connector Type = Housing
- [Gender](#) = Plug
- [Keyed](#) = No
- [Mount](#) = Panel
- [Mounting Ears](#) = Without
- [Mating Connector Lock](#) = Without
- [Jackscrew Type](#) = Male
- PCB Mount Retention = Without

**Electrical Characteristics:**

- Voltage (VAC) = 600

**Body Features:**

- [Connector Configuration](#) = Rectangular
- [Number of Positions](#) = 62
- Coaxial Socket = Without
- [Centerline \(mm \[in\]\)](#) = 5.00 [0.197]
- [Jackscrew](#) = With
- [8/32 Insert](#) = No

**Housing Features:**

- Housing Material = Thermoplastic - GF
- Housing Color = Black
- UL Flammability Rating = UL 94V-0

**Industry Standards:**

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- RoHS/ELV Compliance History = Always was RoHS compliant

**Other:**

- Brand = AMP
- Comment = Housings shown with jackscrew in plug and female jackscrew threads in receptacle. Either can be equipped with female jackscrew threads or jackscrew as necessary.

**Corporate Information**

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

**Quick Links**

- [Check Distributor Inventory](#)
- [Cross Reference Products](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

**Customer Support**

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

**Keep Me Informed**

Receive TE News, Events & Technology Updates

Enter your email address

