



My Cart |

My Part Lists | Sign In/Register

English (Change)



What can we help you find?




- Products
- Industries
- Resources
- About TE
- My Account
- Innovation
- Support Center

Home > Products > RF & Coax > Product Feature Selector > Product Details

## 1-1337428-0 Product Details

[Share](#) [Print](#) [Email](#)

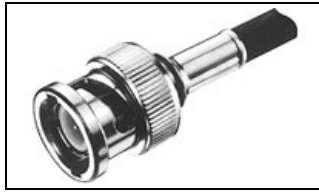

1-1337428-0

TE Internal Number: 1-1337428-0  
 Active

### BNC RF Connectors

Converted to EU RoHS/ELV Compliant (Statement of Compliance)

#### Product Highlights:

- Connector - RF
- Plug
- Connector Style = Plug
- Applies To Coaxial Cable
- Coaxial Cable Termination Type = Crimp

[View all Features](#)

### Quick Links

- [Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [BNC STRAIGHT PLUG CRIMP 75 OHM RG59B/U, 62A/U, 140/...](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- **Product Type** = Connector - RF
- **Gender** = Plug
- **Grade** = Professional
- **Sealed** = No
- **Isolated** = No
- **Dielectric Material** = PTFE
- **Coupling Nut Material** = Brass

#### Mechanical Attachment:

- **Surface Mountable** = No
- **Hardware Included** = No
- **Panel Mount Retention** = Without
- **Hand Tool No.** = 9-1478240-0
- **Interchangeable Die Set Number** = 9-1478242-0

#### Electrical Characteristics:

- **Connector Impedance ( $\Omega$ )** = 75
- **Frequency** = DC - 2 GHz

#### Termination Features:

- **Coaxial Cable Termination Type** = Crimp
- **Crimp Type** = Hex
- **Crimp Dimensions** = 1.75 + 2.6 + 5.6 + 6.5

#### Body Features:

- **Body Style** = Straight
- **Body Material** = Brass
- **Body Plating** = Nickel
- **Polarized** = No
- **Ferrule Type** = Hex
- **Gasket Material** = White Silicone Rubber

#### Contact Features:

- **Center Contact Material** = Brass
- **Center Contact Plating** = Gold

#### Housing Features:

- **Connector Style** = Plug

#### Configuration Features:

- **Coaxial Cable Type (RG/U or Mfg.)** = 140, 210, 59B, 62A, Raychem 9524A1311, Raychem 9524A1811, URM 90
- **Number of Ports** = 1

#### Industry Standards:

- **Government/Industry Qualification** = No
- **RoHS/ELV Compliance** = RoHS compliant, ELV compliant
- **Lead Free Solder Processes** = Not relevant for lead free process
- **RoHS/ELV Compliance History** = Converted to comply with RoHS directive
- **Military Style Number** = UG-1789/U

#### Environmental:

- **Operating Temperature (Max.) ( $^{\circ}$ C)** = 165

#### Conditions for Usage:

- **Applies To** = Coaxial Cable

#### Packaging Features:

- **Packaging Method** = Individual
- **Packaging Quantity** = 50

#### Other:

- **Brand** = Greenpar

### Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

### Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

### Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

### Keep Me Informed



Feedback