


1 - 206062 -5 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

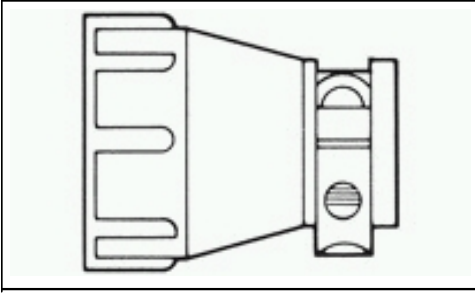

1 - 206062 -5

Active

CPC Accessories

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Cable Clamp
- ? Shell Size = 11
- ? Body Style = Straight
- ? Cable Diameter (Max.) = 8.36 mm
- ? Thermoplastic Cable Clamp Material

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [CABLE CLAMP KIT, STANDARD, SHELL SIZE 11, CPC](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files: ([CAD Format & Compression Information](#))

- ? [2D Drawing](#) (DXF, Version T)
- ? [3D Model](#) (IGES, Version T)
- ? [3D Model](#) (STEP, Version T)

[List all Documents](#)

Additional Information:

- ? [Product Line Information](#)

Additional Product Images:

- ? [Product Usage](#)
- ? [Product Usage](#)
- ? [Product Usage](#)

Related Products:

- ? [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Cable Clamp
- ? [Shell Size](#) = 11
- ? [Body Style](#) = Straight
- ? Thread Size = 5/8 -24
- ? Comment = Packaging includes two screws: Shell sizes 11 -17, screw length 12.70 [.500]; shell size 23, screw length 15.88 [.625].; Bulk packaging to be ordered in multiples of 400 only.; Cable clamps can be threaded directly onto plugs or receptacles, or onto back -shell extenders.; Clamping areas adjustable by inverting or changing inserts.; Components for all cable clamps are packaged unassembled. This includes the cable clamp, two screws, and the clamping inserts.

Body Related Features:

- ? [Cable Diameter \(Max.\) \(mm \[in\]\)](#) = 8.36 [0.329]
- ? [Cable Clamp Material](#) = Thermoplastic
- ? [Cover](#) = Without
- ? Cable Clamp Color = Black
- ? Cable Clamp Flammability Rating = UL94V -1

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ? [Packaging Method](#) = Bulk

Other:

- ? Brand = AMP