


130521 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

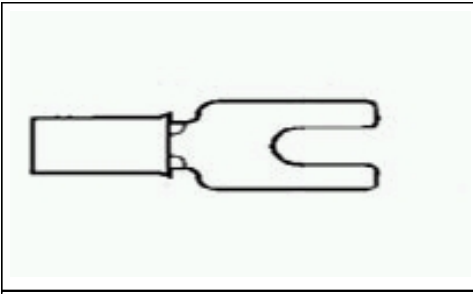

130521

✓ [Active](#)

Ring and Spade Tongue Terminals

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Terminal Shape = Spade Tongue
- ? Receptacle Style = Straight
- ? Body Style = PIDG
- ? Barrel Type = Closed Barrel
- ? Wire/Cable Type = Regular Wire

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [Cosse à fourche](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Terminal Shape](#) = Spade Tongue
- ? [Receptacle Style](#) = Straight
- ? [Body Style](#) = PIDG
- ? [Barrel Type](#) = Closed Barrel
- ? [Wire/Cable Type](#) = Regular Wire
- ? [Insulation](#) = Yes
- ? [Insulation Support](#) = Insulation Support
- ? [Insulation Diameter \(mm \[in\]\)](#) = 3.30 [.130] Max.
- ? Stud Size = M2.5
- ? [Stud Diameter \(mm \[in\]\)](#) = 3.00 [0.118]
- ? [Shape](#) = SPADE -020
- ? [Heavy Duty](#) = No
- ? [Material](#) = Copper
- ? [Finish](#) = Tin
- ? Tongue Material Thickness (mm [in]) = 0.84 [0.033]
- ? Color = Red

Electrical Characteristics:

- ? Voltage (VAC) = 300

Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 0.30 - 1.40 ² [22 - 16]
- ? Wire Range (CMA) = 509 - 3,260
- ? Insulation Sleeve Material = Nylon

Industry Standards:

- ? Government/Industry Qualification = No
- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- ? Temperature Range (°C) = 105

Packaging Related Features:

- ? [Packaging Method](#) = Loose Piece
- ? Packaging Quantity = 100

Other:

- ? Brand = AMP