


1326030-4 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

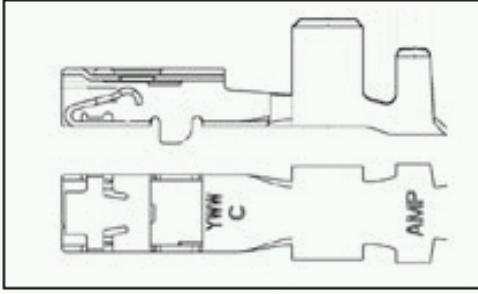

1326030-4

TE Part Number: 1326030-4

Active

Add to Part List

View 3D PDF

Timer Contacts

Always EU RoHS/ELV Compliant ([Statement of Compliance](#))

Product Highlights:

- Contact
- Contact Type = USCAR
- Receptacle
- Wire Range = 3.00-6.00² [12-10] mm [AWG]
- Insulation Diameter = 1.20 - 4.04 mm

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [2.8mm RECEPTACLE UNSEALED](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [2.8 mm Terminal System \(Sealed and Unsealed\)](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version H1)
- [3D Model](#) (IGES, Version H1)
- [3D Model](#) (STEP, Version H1)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Line Drawing](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Contact
- [Gender](#) = Receptacle
- [Insulation Diameter \(mm \[in\]\)](#) = 1.20 - 4.04 [0.047 - 0.161]
- [Tab Fit \(mm \[in\]\)](#) = 2.79 x 0.81 [.110 x .032]

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 3.00-6.00² [12-10]
- [Single Wire Sealing System](#) = No

Contact Related Features:

- [Contact Type](#) = USCAR
- [Contact Material](#) = Copper Alloy
- [Contact Mating Area Plating Material](#) = Bright Tin

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

Conditions for Usage:

- [Terminate To](#) = Wire

Packaging Related Features:

- [Packaging Method](#) = Tape & Reel

Other:

- [GET 0.64 Connector System](#) = No
- [Brand](#) = AMP