


## 144432 -1 Product Details

**Live Product Chat** US Only  
8:30am - 5pm ET, Mon - Fri

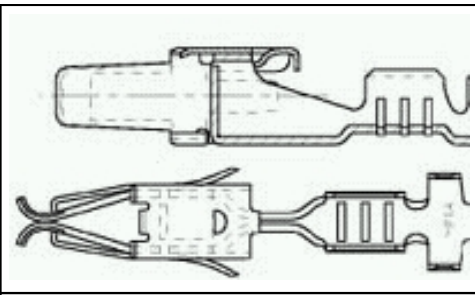

**144432 -1**

[Active](#)

### Timer Contacts

[Always EU RoHS/ELV Compliant](#) ( [Statement of Compliance](#) )

#### Product Highlights:

- ? Contact
- ? Contact Type = Junior -Power -Timer
- ? Receptacle
- ? Wire Range = 1.00 -3.00<sup>2</sup> [17-12] mm [AWG]
- ? Insulation Diameter = 3.50 mm

[View all Features](#) | [Find Similar Products](#)

### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- ? [contact junior power timer](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- ? None Available

#### Product Specifications:

- ? [Terminal, Timer Connector](#) (PDF, English)
- ? [Contacts Junior Power Timer](#) (PDF, English)

#### Application Specifications:

- ? [CRIMPING JUNIOR POWER TIMER RECEPTACLE CONTACT REF. ...](#) (PDF, English)

#### Instruction Sheets:

- ? None Available

#### CAD Files:

- ? None Available

#### Additional Information:

- ? [Product Line Information](#)

#### Additional Product Images:

- ? [Line Drawing](#)

#### Related Products:

- ? [Tooling](#)

[List all Documents](#)

### Product Features

(Please use the Product Drawing for all design activity)

#### Product Type Features:

- ? [Product Type](#) = Contact
- ? [Gender](#) = Receptacle
- ? [Insulation Diameter \(mm \[in\]\)](#) = 3.50 [0.137]
- ? Tab Fit (mm [in]) = 2.79 x 0.81 [.110 x .032]

#### Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 1.00 -3.00<sup>2</sup> [17-12]
- ? Single Wire Sealing System = No

#### Contact Related Features:

- ? [Contact Type](#) = Junior -Power -Timer
- ? [Contact Material](#) = CuSn4
- ? [Contact Mating Area Plating Material](#) = Pre -Tin

#### Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

#### Conditions for Usage:

- ? [Terminate To](#) = Wire

#### Packaging Related Features:

- ? [Packaging Method](#) = Strip

#### Other:

- ? GET 0.64 Connector System = No
- ? Brand = AMP