


## 1 - 829261 - 4 Product Details

**Live Product Chat** US Only  
 8:30am - 5pm ET, Mon - Fri

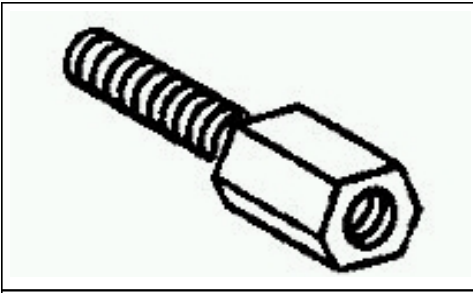

1 - 829261 - 4

[Active](#)

### Hardware (AMPLIMITE)

[Always EU RoHS/ELV Compliant](#) ( [Statement of Compliance](#) )

#### Product Highlights:

- ? Female Screw Locks
- ? Tin Body Finish
- ? Thread Size = M3
- ? Thread Length = 14.20 mm
- ? Screwlock Style = Screwlock Only

[View all Features](#) | 
 [Find Similar Products](#)

### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling Product Feature Selector](#)
- [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- ? [screwlock female hd series](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- ? None Available

#### Product Specifications:

- ? None Available

#### Application Specifications:

- ? None Available

#### Instruction Sheets:

- ? None Available

#### CAD Files:

- ? None Available

#### Additional Information:

- ? [Product Line Information](#)

#### Related Products:

- ? [Tooling](#)

[List all Documents](#)

### Product Features

(Please use the Product Drawing for all design activity)

#### Product Type Features:

- ? [Product Type](#) = Female Screw Locks
- ? [Body Finish](#) = Tin
- ? [Thread Size](#) = M3
- ? Body Material = Brass
- ? Comment = For Rear Panel Mount.

#### Body Related Features:

- ? [Thread Length \(mm \[in\]\)](#) = 14.20 [0.559]
- ? Screwlock Style = Screwlock Only

#### Industry Standards:

- ? Government/Industry Qualification = No
- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

#### Packaging Related Features:

- ? [Packaging Method](#) = Individual

#### Other:

- ? Brand = AMP