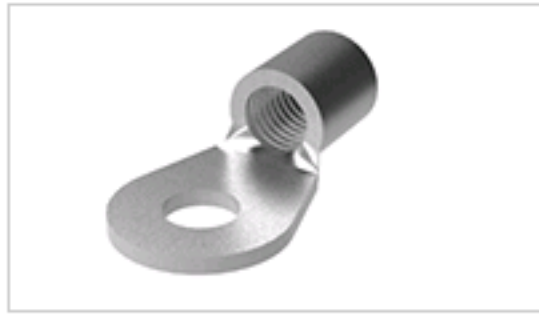


# 2-322796-1 Product Details

[Share](#) | [Print](#) | [Email](#)


Active

## Ring and Spade Tongue Terminals

STRATO R 22-16COMM 22-18MIL 4

**2-322796-1**

TE Internal Number: 2-322796-1

**Product Highlights** [View All](#)

- Terminal Shape = Ring Tongue
- Receptacle Style = Straight
- Body Style = SOLISTRAND
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

[Pricing & Availability](#)

[Request Sample](#)

[Add to My Part List](#)

[Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

**Please Note:**  
Use the Product Drawing for all design activity

Product Type Features	
Receptacle Style	Straight
Barrel Type	Closed Barrel
Wire/Cable Type	Regular Wire
Insulation	No
Insulation Support	Non-Insulation Support
Stud Size	4
Shape	RING-049
Heavy Duty	No
Finish	Nickel

Termination Features	
Wire/Cable Size (CMA)	509 - 3,260

Dimensions	
Stud Diameter (mm [in])	3.02 [0.119]

Body Features	
Body Style	SOLISTRAND
Wire Range (mm [AWG])	0.30-1.42 <sup>2</sup> [22-16]
Material	Copper

Contact Features	
Terminal Shape	Ring Tongue

Industry Standards	
Government/Industry Qualification	No
RoHS/ELV Compliance	RoHS compliant, ELV compliant
Lead Free Solder Processes	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant

Packaging Features	
Packaging Method	Loose Piece

Other	
Brand	TE Connectivity

**Related Products**

Not quite the product you're looking for?  
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)