


3-1447221 -5 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

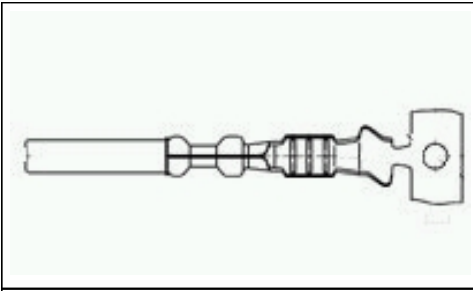

Super Seal 1.0mm

[Converted to EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Contact
- ? Contact Gender = Receptacle
- ? Wire Range = 0.30 -0.60² [22-20] mm [AWG]
- ? Strip
- ? Copper Alloy Contact Material

[View all Features](#) | [Find Similar Products](#)

3-1447221 -5

[Active](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Documents are temporarily unavailable. We are working hard to correct the problem. Please try again later.

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Contact
- ? [Industry Application](#) = Standard

Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 0.30 -0.60² [22-20]

Contact Related Features:

- ? Contact Gender = Receptacle
- ? Contact Material = Copper Alloy

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Converted to comply with RoHS directive

Packaging Related Features:

- ? [Packaging Method](#) = Strip

Other:

- ? Brand = AMP