


5-1735480-6 Product Details

[Share](#) [Print](#) [Email](#)

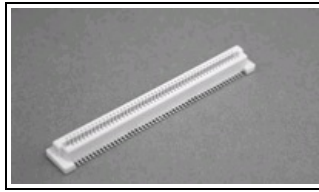

5-1735480-6

TE Internal Number: 5-1735480-6
Active

[View 3D PDF](#)

0.8mm Free Height

Not EU RoHS or ELV Compliant

Product Highlights:

- Connector Style = Receptacle
- 140 Positions
- PCB Mounting Orientation = Vertical
- Board-to-Board Stack Height = 17.00 mm, 18.00 mm, 19.00 mm, 20.00 mm
- Gold (8) Contact Plating, Mating Area, Material

[View all Features](#)

Quick Links

- [Pricing & Availability](#)
- [Search for Tooling](#)
- [View Mating Products \(17\)](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [RECEPTACLE 17MM HEIGHT FH 0.8MM PITCH B-TB CONNECTO... \(PDF, English\)](#)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- [Free Height 0.8 mm Pitch Board-to-Board Connector \(SMT\) \(PDF, English\)](#)

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: (CAD Format & Compression Information)

- [2D Drawing \(DXF, Version A\)](#)
- [3D Model \(IGES, Version A\)](#)
- [3D Model \(STEP, Version A\)](#)

Additional Product Images:

- [Product Photo](#)

Related Products:

- [Tooling](#)
- [Mating Products \(17\)](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- PCB Mounting Orientation = Vertical
- Family Name = Free Height
- Keyed = Yes
- Sealant = Without

Termination Features:

- Solder Tail Contact Plating = Tin over Nickel

Dimensions:

- Board-to-Board Stack Height (mm[in]) = 17.00 [0.669], 18.00 [0.709], 19.00 [0.748], 20.00 [0.787]
- Height = 17H

Body Features:

- Locating Post(s) = With
- Vacuum Cover = Without
- Locating Post Length = 0.5 mm

Contact Features:

- Contact Plating, Mating Area, Material = Gold (8)
- Contact Base Material = Copper Alloy

Housing Features:

- Connector Style = Receptacle
- Housing Color = Natural
- Housing Material = Liquid Crystal Polymer (LCP)
- UL Flammability Rating = UL 94V-0
- Housing Material Temperature = High

Configuration Features:

- Number of Positions = 140
- Number of Rows = Dual

Industry Standards:

- RoHS/ELV Compliance = Not ELV/RoHS compliant
- Lead Free Solder Processes = Reflow solder capable to 245°C, Reflow solder capable to 260°C

Packaging Features:

- Packaging Method = Tube

Other:

- Brand = AMP

Corporate Information

[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)
[Terms & Conditions](#)
[Privacy Policy](#)

Quick Links

[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)

Keep Me Informed

