


5051426-4 Product Details

[Live Product Chat](#)

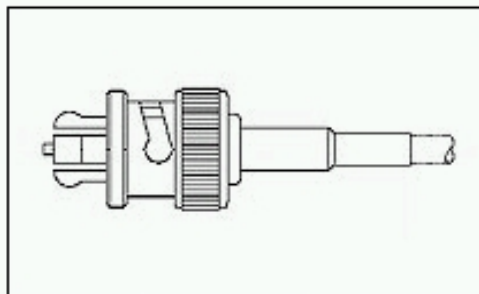

5051426-4

TE Part Number: 5051426-4

[Active](#)

[Add to Part List](#)

SHV RF Connectors

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Connector
- Plug
- Coaxial Cable Type (RG/U or Mfg.) = 58, 58A, 58B, 58C
- Coaxial Cable Termination Type = Crimp
- Nickel Body Plating

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [CONNECTOR, COAXIAL, PLUG, SERIES SHV \(PDF, English\)](#)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version A1)
- [3D Model](#) (IGES, Version A1)
- [3D Model](#) (STEP, Version A1)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Connector
- [Gender](#) = Plug
- Crimp Type = Dual
- Dielectric Material = TEFLON

Mechanical Attachment:

- Panel Attachment = Without

Termination Related Features:

- Coaxial Cable Termination Type = Crimp

Body Related Features:

- [Body Plating](#) = Nickel

Contact Related Features:

- Center Contact Plating = Gold

Configuration Related Features:

- [Coaxial Cable Type \(RG/U or Mfg.\)](#) = 58, 58A, 58B, 58C

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Terminate To = Coaxial Cable

Other:

- Brand = AMP