


5 - 583259 - 3 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

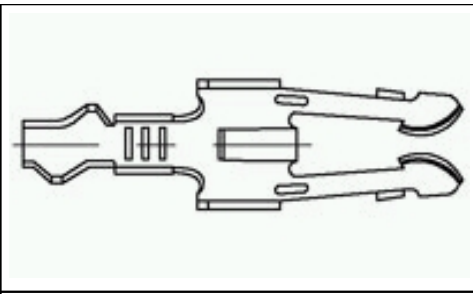

5 - 583259 - 3

[Active](#)

.125, .156 Centerline Connectors (Modified Fork)

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Contact
- ? Wire Range = 0.20 - 0.60 ² [24 - 20] mm [AWG]
- ? Strip

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

? None Available

Catalog Pages/Data Sheets:

? None Available

Product Specifications:

? None Available

Application Specifications:

? None Available

Instruction Sheets:

? None Available

CAD Files:

? None Available

Additional Information:

? [Product Line Information](#)

Related Products:

? [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Contact
- ? Insulation Diameter (mm [in]) = 1.27 - 2.29 [0.050 - 0.090]
- ? Comment = Matte tin plate in crimp area.

Body Related Features:

? [Wire Range \(mm \[AWG\]\)](#) = 0.20 - 0.60 ² [24 - 20]

Contact Related Features:

- ? Contact Material = Phosphor Bronze
- ? Contact Mating Area Plating Material = Select Gold (30) over Nickel (30)

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Wave solder capable to 240°C
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

? [Packaging Method](#) = Strip

Other:

? Brand = Tyco Electronics