


## 603328-1 Product Details

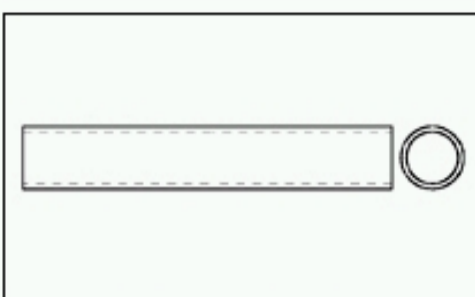


### 603328-1

TE Part Number: 603328-1

 **Active**
 [Add to Part List](#)

## Heat Shrink Tubing

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

### Product Highlights:

- Jacket Tubing
- General Purpose Application
- Operating Temperature = -30 - 125 °C
- Inside Diameter (Min-Max) = 6.35 - 12.70 mm
- Without Sealant

[View all Features](#) | [Find Similar Products](#)

## Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)



## Documentation & Additional Information

### Product Drawings:

- [AMPSULATION VFP21 AND FP21, 1/2 IN. EXPANDED ID \(PDF, English\)](#)

### Catalog Pages/Data Sheets:

- None Available

### Product Specifications:

- None Available

### Application Specifications:

- [Heat Shrink Tubing \(PDF, English\)](#)

### Instruction Sheets:

- None Available

### CAD Files:

- None Available

### Additional Information:

- [Product Line Information](#)

### Related Products:

- [Tooling](#)

[List all Documents](#)

## Product Features (Please use the Product Drawing for all design activity)

### Product Type Features:

- [Product Type](#) = Jacket Tubing
- [Sealant](#) = Without
- Style = VFP21
- Size = 12.70 [.500]
- Color = Black
- Material = Polyolefin
- Proprietary Name = AMPSULATION

### Body Related Features:

- [Marked](#) = Yes
- [Shrink Ratio](#) = 2:1
- [Wall Style](#) = Thin
- [Wall Thickness - Full Recovery \(Nominal\) \(mm \[in\]\)](#) = 0.64 [0.025]
- [Length \(M \[ft\]\)](#) = 1.219 [3.99]
- Marking Color = White

### Housing Related Features:

- [Inside Diameter \(Min-Max\) \(mm \[in\]\)](#) = 6.35 - 12.70 [0.250 - 0.500]

### Industry Standards:

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

### Conditions for Usage:

- Operating Temperature (°C) = -30 - +125

### Operation/Application:

- Application = General Purpose

### Packaging Related Features:

- Packaging Method = Bag
- Weight per Linear Foot (g [lb]) = 4.649 [0.0103]

### Other:

- Brand = AMP