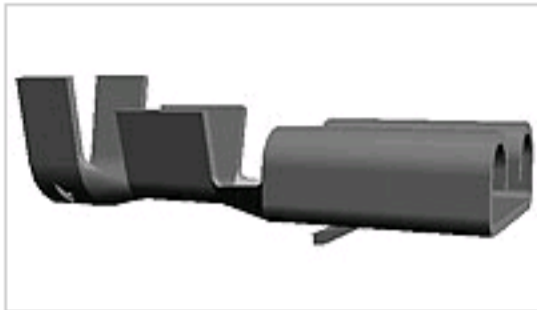


60838-1 Product Details

[Share](#) | [Print](#) | [Email](#)


Multiple Circuit Housings with Tabs & Receptacles

.250 FF REC 0126TPBR
60838-1
TE Internal Number: 60838-1

Active
 [View 3D PDF](#)

Product Highlights [View All](#)

- Contact
- Contact Type = Receptacle
- Mating Area Interface Dimensions = 6.35 x 0.81 mm
- Wire Range = 0.30-0.90² [22-18] mm [AWG]
- Insulation Diameter = 2.16-3.18 [.085-.125] mm [in]

- [Pricing & Availability](#)
- [Request Sample](#)
- [Add to My Part List](#)
- [Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

Please Note:
Use the Product Drawing for all design activity

Product Type Features	
Product Type	Contact
Receptacle Style	Straight
Wire/Cable Type	Regular Wire
Finish	Tin
Insertion Force	Normal
Insulation Support	With
FASTON	Yes
Termination Features	
Crimp Type	F-Crimp
Dimensions	
Mating Area Interface Dimensions (mm [in])	6.35 x 0.81 [.250 x .032]
Insulation Diameter (mm [in])	2.16-3.18 [.085-.125]

Body Features	
Wire Range (mm [AWG])	0.30-0.90 ² [22-18]
Material	Brass
Contact Features	
Contact Type	Receptacle
Industry Standards	
RoHS/ELV Compliance	RoHS compliant, ELV compliant
Lead Free Solder Processes	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant
Packaging Features	
Packaging Method	Loose Piece
Other	
Line	FASTIN-FASTON .250
Brand	AMP

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information
[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)
[Terms & Conditions](#)
[Privacy Policy](#)
[Global Accessibility Statement](#)

Quick Links
[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support
[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)

Keep Me Informed